


Vernier Caliper Nib Style Jaw

Item number: 160-153

Images

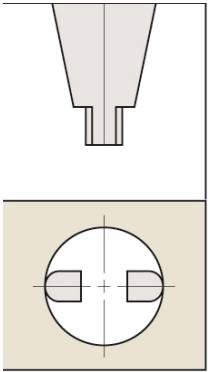

Description

These vernier calipers with nib style jaws come with or without fine adjustment.


They offer you the following benefits:

- For the metric only models the top offset vernier scale allows you to directly read the inside dimensions without having to add the nib widths.
- Main scale and vernier scale satin chrome finish gives you high readability.

Features

With upper locking screw:	Yes
Range:	0 - 24 "
Range:	0 - 600 mm
Graduation:	0,02 mm/ 0,001"
Inside measuring from:	20.1 mm
Delivered:	In a box
Max. Permissible Error E MPE:	±0,05 mm
Max. Permissible Error S MPE:	±0,05 mm
Mass:	1400 g

Dimensions

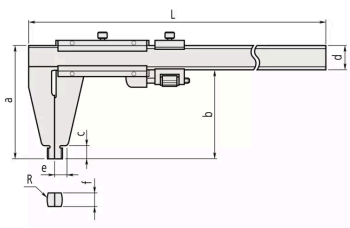

a: 125 mm

b: 100 mm

c: 18 mm

d: 25 mm

e: 14.8 mm

f: 6 mm

R: 10 mm