
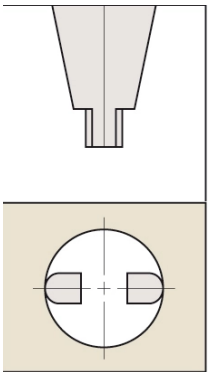


Vernier Caliper Nib Style Jaw

Item number: 160-155

Images

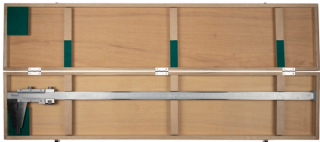

Description

These vernier calipers with nib style jaws come with or without fine adjustment. They offer you the following benefits:

- For the metric only models the top offset vernier scale allows you to directly read the inside dimensions without having to add the nib widths.
- Main scale and vernier scale satin chrome finish gives you high readability.

Features

With upper locking screw:	Yes
Range:	0 - 40 "
Range:	0 - 1,000 mm
Graduation:	0,02 mm/ 0,001"
Inside measuring from:	20.1 mm


Delivered: In a box

Max. Permissible Error E MPE: $\pm 0,07$ mm

Max. Permissible Error S MPE: $\pm 0,07$ mm

Mass: 3500 g

Dimensions

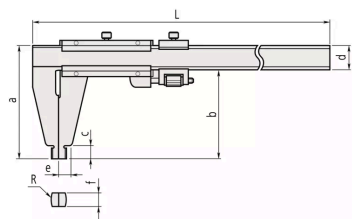

a: 172 mm

b: 140 mm

c: 24 mm

d: 32 mm

e: 17 mm

f: 10 mm

R: 10 mm