


Dial Gauge, Lug Back, ISO Type

Item number: 1913A-10

Images

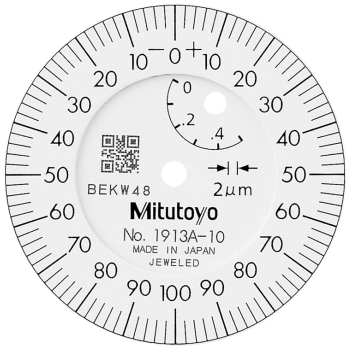

Description

Compact Type, Extra Small Diameter - Metric

This is a compact, dial indicator with a bezel \varnothing 31 / 36 mm. It offers you the following benefits:

- It is ideal for use in applications where space is limited.

Features

Digital/Analog:	Analog
Inch-Metric:	Metric
Delivered:	With certificate of inspection
Range:	0.5 mm
Range per rev.:	0,2 mm
Dial reading:	0-100-0
Graduation:	0.002 mm

MPE any 1/10 revolution:	2.5 µm
MPE any 1/2 revolution:	4.5 µm
MPE any 1 revolution:	5 µm
MPE measuring range:	6 µm
H MPE (Hysteresis):	2.5 µm
R MPE (Repeatability):	1 µm
Measuring force:	0,3-1,8 N
Mass:	55 g
Stem:	8 mm
Contact point:	Carbide tipped, thread: M 2.5 x 0.45 mm
Balanced dial:	Yes
Type:	EN ISO Standard

Dimensions

A: 15.5 mm
B: 39.4 mm
C: 31 mm
D: 12.7 mm
E: 19.4 mm
F: 15.1 mm
G: 8.9 mm
H: 30 mm
I: 6 mm

Spare parts

Consumable spares:

Contact Element Ball Point, M2,5x0,45

8,3mm Length, Metric
 Art No. 21AZA319
 Suggested retail price: 17.00 €*