

Digital Height Gauge Double Column

Item number: 192-630-10

Images



Description


A Mitutoyo digital height gauge, twin column design. Standard-type functionality. Digimatic data output. An extensive range of accessories extends the application range.

Features

Model:	HD-12"AX
Digital/Analog:	Digital
Range:	0 - 12 "
Digital step:	0.0005/0.0002" or 0.01/0.005 mm
Delivered:	Including carbide tipped scriber, scriber clamp and SR44 battery
Max. Permissible Error E MPE:	±0,001"/±0,02 mm
Max. Permissible Error J MPE:	±0.02 mm/0.001"
Display:	LCD, Character Height: 11 mm
Max. response speed:	500 mm/s
ON/OFF:	Yes
ABS / INC (INC ZERO):	Yes
PRESET (2 values):	Yes
DATA (output with cable) / HOLD (display value):	Yes
Low voltage alarm:	Yes
±SWITCHING:	Yes

Mm / inch switching:	Yes
Inch-Metric:	Inch/Metric
Power supply:	1 battery SR-44
Battery life:	approx. 3500 hours
Mass:	6.5 kg

Dimensions

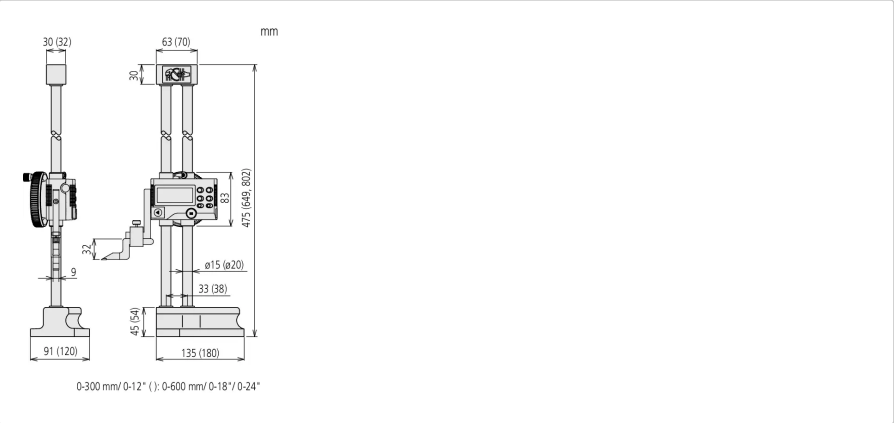

Accessories

Optional accessories:

Promotion!



the standard in world metrology software





USB-ITPAK Vers. 3.0

USB Dongle + Manual (Software available Online)

Art No. 06AGR543

Promo price: **268.00 €***

~~Suggested retail price: 340.00 €*~~



Digimatic Cable, Flat Straight Type

1 m

Art No. 905338

Suggested retail price: **37.00 €***



Digimatic Cable, Flat Straight Type

2 m

Art No. 905409

Suggested retail price: **44.00 €***

Promotion!



USB Input Tool Direct (Digimatic to USB)

2m Cable, Digimatic/Digimatic 2, Flat
Straight Type

Art No. 06AFM380F

Promo price: **98.00 €***

Suggested retail price: ~~124.00 €*~~

Promotion!



U-WAVE-T, Buzzer Type

Wireless Transmitter

Art No. 02AZD880G

Promo price: **129.00 €***

Suggested retail price: ~~187.00 €*~~

Promotion!



U-WAVE-T, IP67 Type

Wireless Transmitter

Art No. 02AZD730G

Promo price: **129.00 €***

Suggested retail price: ~~187.00 €*~~

Promotion!



Connection Cable F for U- WAVE

Straight, without Data Button

Art No. 02AZD790F

Promo price: **68.00 €***

Suggested retail price: ~~98.00 €*~~



Holding Bar for Swivel Clamp

6,25x12,7mm, 2" Length

Art No. 953639

Suggested retail price: **19.50 €***



Holding Bar for Swivel Clamp

12,7x6,35mm, 4" Length
Art No. 900306
Suggested retail price: **17.30 €***



Swivel Clamp

for D= 4/9,52mm, Dovetail
Art No. 900322
Suggested retail price: **26.50 €***



Center Master

for 6,35x12,7mm
Art No. 900581
Suggested retail price: **161.00 €***



Depth Gauge Attachment

for 12,7mm x 6,35mm
Art No. 900878
Suggested retail price: **59.00 €***

Standard accessories:



Scriber Clamp

for 6,35x12,7mm Scriber
Art No. 901385
Suggested retail price: **23.80 €***



Carbide Tipped Scriber

6,35x12,7mm, 60mm Length
Art No. 900258
Suggested retail price: **81.00 €***



Vinyl Cover Series 192

300mm
Art No. 450291
Suggested retail price: **7.40 €***

Spare parts

Consumable spares:



Battery SR44 1,5 V

Art No. 938882
Suggested retail price: **7.00 €***

