

Digital Height Gauge Double Column

Item number: 192-631-10

Images



Description


A Mitutoyo digital height gauge, twin column design. Standard-type functionality. Digimatic data output. An extensive range of accessories extends the application range.

Features

Model:	HD-18"AX
Digital/Analog:	Digital
Range:	0 - 18 "
Digital step:	0.0005/0.0002" or 0.01/0.005 mm
Delivered:	Including carbide tipped scriber, scriber clamp and SR44 battery
Max. Permissible Error E MPE:	$\pm 0,002"/\pm 0,05$ mm
Max. Permissible Error J MPE:	± 0.05 mm/0.002"
Display:	LCD, Character Height: 11 mm
Max. response speed:	500 mm/s
ON/OFF:	Yes
ABS / INC (INC ZERO):	Yes
PRESET (2 values):	Yes
DATA (output with cable) / HOLD (display value):	Yes
Low voltage alarm:	Yes
\pmSWITCHING:	Yes

Mm / inch switching:	Yes
Inch-Metric:	Inch/Metric
Power supply:	1 battery SR-44
Battery life:	approx. 3500 hours
Mass:	10.4 kg

Dimensions

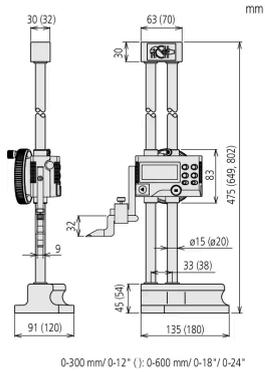

Accessories

Optional accessories:

Promotion!





the standard in world
metrology software



USB-ITPAK Vers. 3.0

USB Dongle + Manual (Software available Online)

Art No. 06AGR543

Promo price: **268.00 €***

Suggested retail price: ~~340.00 €*~~

USB-ITPAK



Digimatic Cable, Flat Straight Type

1 m
Art No. 905338
Suggested retail price: 37.00 €*



Digimatic Cable, Flat Straight Type

2 m
Art No. 905409
Suggested retail price: 44.00 €*

Promotion!



USB Input Tool Direct (Digimatic to USB)

2m Cable, Digimatic/Digimatic 2, Flat
Straight Type

Art No. 06AFM380F

Promo price: **98.00 €***

Suggested retail price: ~~124.00 €*~~

Promotion!



U-WAVE-T, Buzzer Type

Wireless Transmitter

Art No. 02AZD880G

Promo price: **129.00 €***

Suggested retail price: ~~187.00 €*~~

Promotion!



U-WAVE-T, IP67 Type

Wireless Transmitter

Art No. 02AZD730G

Promo price: **129.00 €***

Suggested retail price: ~~187.00 €*~~

Promotion!



Connection Cable F for U- WAVE

Straight, without Data Button

Art No. 02AZD790F

Promo price: **68.00 €***

Suggested retail price: ~~98.00 €*~~



Holding Bar for Swivel Clamp

6,25x12,7mm, 2" Length

Art No. 953639

Suggested retail price: **19.50 €***

Holding Bar for Swivel Clamp

12,7x6,35mm, 4" Length
Art No. 900306
Suggested retail price: 17.30 €*



Swivel Clamp

for D= 4/9,52mm, Dovetail
Art No. 900322
Suggested retail price: 26.50 €*



Center Master

for 6,35x12,7mm
Art No. 900581
Suggested retail price: 161.00 €*



Depth Gauge Attachment

for 12,7mm x 6,35mm
Art No. 900878
Suggested retail price: 59.00 €*



Standard accessories:



Scriber Clamp

for 6,35x12,7mm Scriber
Art No. 901385
Suggested retail price: 23.80 €*



Carbide Tipped Scriber

6,35x12,7mm, 60mm Length
Art No. 900258
Suggested retail price: 81.00 €*



Vinyl Cover Series 192

600mm
Art No. 450292
Suggested retail price: 5.80 €*

Spare parts

Consumable spares:



Battery SR44 1,5 V

Art No. 938882
Suggested retail price: 7.00 €*

