

# Digital Height Gauge Double Column

Item number: 192-632-10

## Images



## Description


A Mitutoyo digital height gauge, twin column design. Standard-type functionality. Digimatic data output. An extensive range of accessories extends the application range.

## Features

|                                                  |                                                                  |
|--------------------------------------------------|------------------------------------------------------------------|
| Model:                                           | HD-24"AX                                                         |
| Digital/Analog:                                  | Digital                                                          |
| Range:                                           | 0 - 24 "                                                         |
| Digital step:                                    | 0.0005/0.0002" or 0.01/0.005 mm                                  |
| Delivered:                                       | Including carbide tipped scriber, scriber clamp and SR44 battery |
| Max. Permissible Error E MPE:                    | ±0,002"/±0,05 mm                                                 |
| Max. Permissible Error J MPE:                    | ±0.05 mm/0.002"                                                  |
| Display:                                         | LCD, Character Height: 11 mm                                     |
| Max. response speed:                             | 500 mm/s                                                         |
| ON/OFF:                                          | Yes                                                              |
| ABS / INC (INC ZERO):                            | Yes                                                              |
| PRESET (2 values):                               | Yes                                                              |
| DATA (output with cable) / HOLD (display value): | Yes                                                              |
| Low voltage alarm:                               | Yes                                                              |
| ±SWITCHING:                                      | Yes                                                              |

|                             |                    |
|-----------------------------|--------------------|
| <b>Mm / inch switching:</b> | Yes                |
| <b>Inch-Metric:</b>         | Inch/Metric        |
| <b>Power supply:</b>        | 1 battery SR-44    |
| <b>Battery life:</b>        | approx. 3500 hours |
| <b>Mass:</b>                | 10.4 kg            |

Dimensions

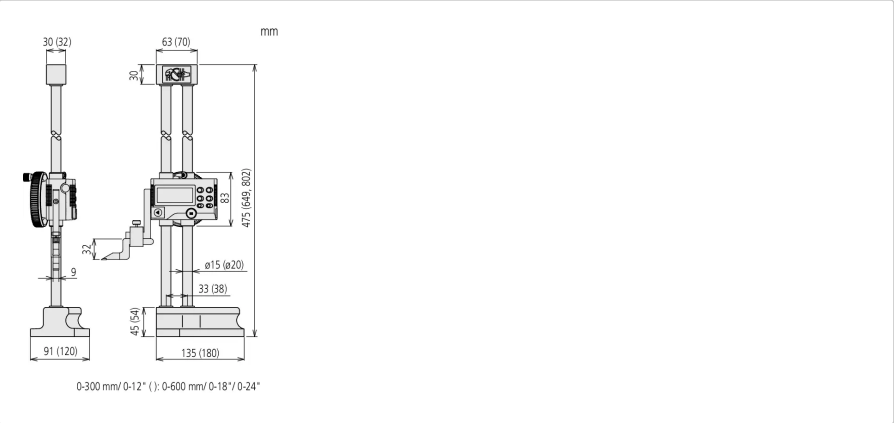

Accessories

Optional accessories:

Promotion!

Mitutoyo

MiCAT

the standard in world metrology software

MeasurLink

USB-ITPAK

**USB-ITPAK Vers. 3.0**

USB Dongle + Manual (Software available Online)

Art No. 06AGR543

Promo price: **268.00 €\***

Suggested retail price: ~~340.00 €\*~~



**Digimatic Cable, Flat Straight Type**

1 m

Art No. 905338

Suggested retail price: **37.00 €\***



**Digimatic Cable, Flat Straight Type**

2 m

Art No. 905409

Suggested retail price: **44.00 €\***

Promotion!



### USB Input Tool Direct (Digimatic to USB)

2m Cable, Digimatic/Digimatic 2, Flat  
Straight Type

Art No. 06AFM380F

Promo price: **98.00 €\***

Suggested retail price: ~~124.00 €\*~~

Promotion!



### U-WAVE-T, Buzzer Type

Wireless Transmitter

Art No. 02AZD880G

Promo price: **129.00 €\***

Suggested retail price: ~~187.00 €\*~~

Promotion!



### U-WAVE-T, IP67 Type

Wireless Transmitter

Art No. 02AZD730G

Promo price: **129.00 €\***

Suggested retail price: ~~187.00 €\*~~

Promotion!



### Connection Cable F for U- WAVE

Straight, without Data Button

Art No. 02AZD790F

Promo price: **68.00 €\***

Suggested retail price: ~~98.00 €\*~~



### Holding Bar for Swivel Clamp

6,25x12,7mm, 2" Length

Art No. 953639

Suggested retail price: **19.50 €\***



### Holding Bar for Swivel Clamp

12,7x6,35mm, 4" Length  
Art No. 900306  
Suggested retail price: **17.30 €\***



### Swivel Clamp

for D= 4/9,52mm, Dovetail  
Art No. 900322  
Suggested retail price: **26.50 €\***



### Center Master

for 6,35x12,7mm  
Art No. 900581  
Suggested retail price: **161.00 €\***



### Depth Gauge Attachment

for 12,7mm x 6,35mm  
Art No. 900878  
Suggested retail price: **59.00 €\***

Standard accessories:



### Scriber Clamp

for 6,35x12,7mm Scriber  
Art No. 901385  
Suggested retail price: **23.80 €\***



### Carbide Tipped Scriber

6,35x12,7mm, 60mm Length  
Art No. 900258  
Suggested retail price: **81.00 €\***



### Vinyl Cover Series 192

600mm  
Art No. 450292  
Suggested retail price: **5.80 €\***

## Spare parts

Consumable spares:



### Battery SR44 1,5 V

Art No. 938882  
Suggested retail price: **7.00 €\***

