


Digital Height Gauge Double Column

Item number: 192-672-10

Images

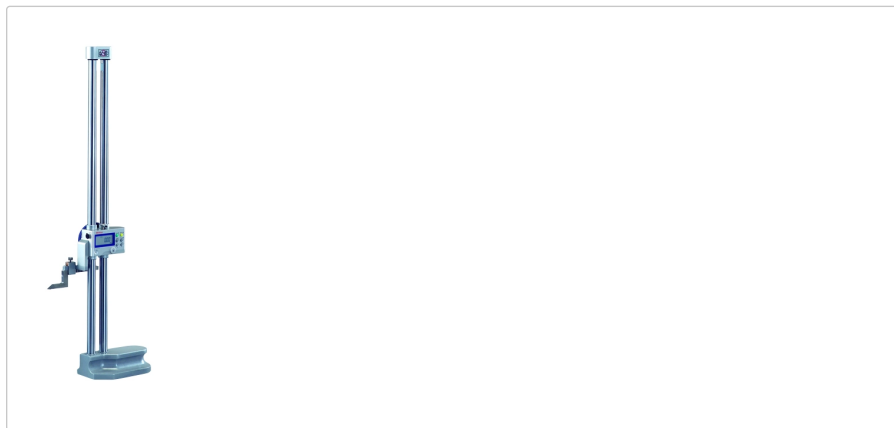

Description

A Mitutoyo digital height gauge, twin column design. Multi-functional type. Digimatic data output. An extensive range of accessories extends the application range.

Features

Model:	HDM-24"AX
Digital/Analog:	Digital
Range:	0 - 24 "
Digital step:	0.0005/0.0002" or 0.01/0.005 mm
Delivered:	Including carbide tipped scriber, scriber clamp and SR44 battery
Max. Permissible Error E MPE:	$\pm 0.0015"/\pm 0.04$ mm
Max. Permissible Error J MPE:	± 0.04 mm/0.0015"
Display:	LCD, Character Height: 11 mm
Max. response speed:	500 mm/s
ON/OFF:	Yes
ABS / INC (INC ZERO):	Yes
PRESET (2 values):	Yes
Touch-trigger probe:	Yes
Stylus tip diameter compensation:	Yes
DATA (output with cable) / HOLD (display value):	Yes
Low voltage alarm:	Yes
\pmSWITCHING:	Yes
Mm / inch switching:	Yes
Inch-Metric:	Inch/Metric
Power supply:	1 battery SR-44


Battery life:

approx. 3500 hours

Mass:

9.5 kg

Dimensions

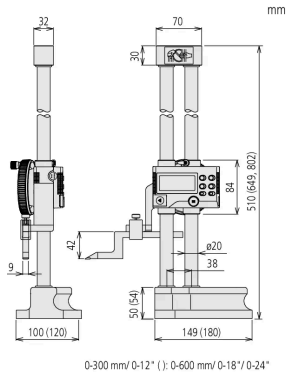

Accessories

Optional accessories:

Promotion!

Mitutoyo

MiCAT
the standard in world metrology software
measurLink

USB-ITPAK Vers. 3.0

USB Dongle + Manual (Software available Online)

Art No. 06AGR543

Promo price: 268.00 €*

Suggested retail price: ~~340.00 €*~~

USB-ITPAK



Bi-Directional Touch Trigger Probe

for Series 192, Inch

Art No. 192-008

Suggested retail price: 606.00 €*



Digimatic Cable, Flat Straight Type

1 m

Art No. 905338

Suggested retail price: 37.00 €*



Digimatic Cable, Flat Straight Type

2 m
Art No. 905409
Suggested retail price: 44.00 €*
*including VAT

Promotion!



USB Input Tool Direct (Digimatic to USB)

2m Cable, Digimatic/Digimatic 2, Flat Straight Type
Art No. 06AFM380F
Promo price: **98.00 €*
Suggested retail price: 124.00 €*
*including VAT**

Promotion!



U-WAVE-T, Buzzer Type

Wireless Transmitter
Art No. 02AZD880G
Promo price: **129.00 €*
Suggested retail price: 187.00 €*
*including VAT**

Promotion!



U-WAVE-T, IP67 Type

Wireless Transmitter
Art No. 02AZD730G
Promo price: **129.00 €*
Suggested retail price: 187.00 €*
*including VAT**

Promotion!



Connection Cable F for U-WAVE

Straight, without Data Button
Art No. 02AZD790F
Promo price: **68.00 €*
Suggested retail price: 98.00 €*
*including VAT**

Holding Bar for Swivel Clamp

6,25x12,7mm, 2" Length
Art No. 953639
Suggested retail price: 19.50 €*



Holding Bar for Swivel Clamp

12,7x6,35mm, 4" Length
Art No. 900306
Suggested retail price: 17.30 €*



Swivel Clamp

for D= 4/9,52mm, Dovetail
Art No. 900322
Suggested retail price: 26.50 €*



Depth Gauge Attachment

for 12,7mm x 6,35mm
Art No. 900878
Suggested retail price: 59.00 €*



Center Master

for 6,35x12,7mm
Art No. 900581
Suggested retail price: 161.00 €*





Contact Sensor

for Height Gauges

Art No. 900872

Suggested retail price: 135.00 €*

Standard accessories:



Scriber Clamp

for 6,35x12,7mm Scriber

Art No. 901385

Suggested retail price: 23.80 €*



Carbide Tipped Scriber

6,35x12,7mm, 150mm Length

Art No. 905201

Suggested retail price: 137.00 €*

Spare parts

Consumable spares:



Battery SR44 1,5 V

Art No. 938882

Suggested retail price: 7.00 €*

