


Digit Outside Micrometer

Item number: 193-112

Images

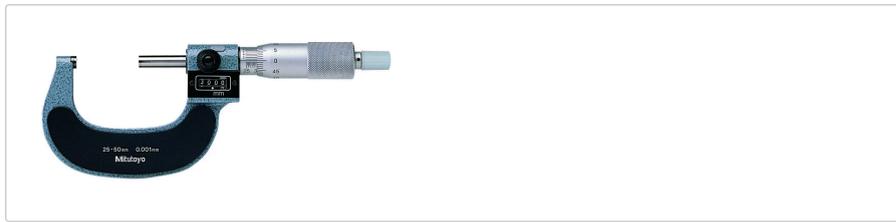

Description

A mechanical-digit Mitutoyo micrometer with a vernier scale on the sleeve to provide high resolution. The highly stable frame incorporates a heat shield to preserve accuracy over extended measuring sessions. A ratchet stop guarantees repeatable measurement.

Features

Digital/Analog:	Analog
Inch-Metric:	Metric
Range:	25 - 50 mm
Graduation:	0,001 mm
Max. Permissible Error J MPE:	$\pm 2 \mu\text{m}$
Delivered:	Including box, setting standard, spanner
Flatness:	0,6 μm
Parallelism:	2 μm
Measuring face:	Carbide-tipped, micro-lap finish
Measuring spindle:	With spindle lock, $\varnothing 6,35$ mm, spindle pitch 0,5 mm
Scale:	Thimble and sleeve satin chrome finish, $\varnothing 18$ mm
Measuring force:	5 - 15 N
Mass:	275 g

Dimensions

L: 55 mm
a: 2 mm
b: 8 mm
c: 32 mm

Accessories

Optional accessories:

