


Digit Outside Micrometer

Item number: 193-114

Images

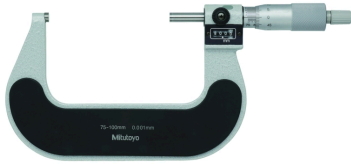


Description

A mechanical-digit Mitutoyo micrometer with a vernier scale on the sleeve to provide high resolution. The highly stable frame incorporates a heat shield to preserve accuracy over extended measuring sessions. A ratchet stop guarantees repeatable measurement.

Features

Digital/Analog:	Analog
Inch-Metric:	Metric
Range:	75 - 100 mm
Graduation:	0,001 mm
Max. Permissible Error J MPE:	±3 µm
Delivered:	Including box, setting standard, spanner
Flatness:	0,6 µm
Parallelism:	3 µm
Measuring face:	Carbide-tipped, micro-lap finish
Measuring spindle:	With spindle lock, ø6,35 mm, spindle pitch 0,5 mm
Scale:	Thimble and sleeve satin chrome finish, ø18 mm
Measuring force:	5 - 15 N
Mass:	489 g

Dimensions

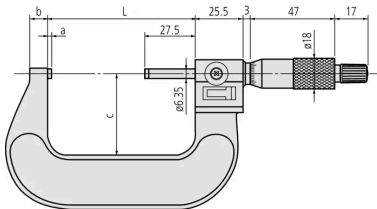

- L: 105 mm
- a: 2 mm
- b: 9 mm
- c: 57 mm

Accessories

Optional accessories:

Promotion!



Micrometer Stand, Adjustable Angle Type

for Micrometer 0-100mm/0-4"

Art No. 156-101-10

Promo price: **56.00 €***

Suggested retail price: ~~70.00 €*~~

Standard accessories:



Micrometer Setting Standard

Length: 100mm

Art No. 167-104

Suggested retail price: **38.00 €***