

Digit Outside Micrometer

Item number: 193-211

Images




Description

A mechanical-digit Mitutoyo micrometer with a vernier scale on the sleeve to provide high resolution. The highly stable frame incorporates a heat shield to preserve accuracy over extended measuring sessions. A friction thimble guarantees repeatable measurement.

Features

Digital/Analog:	Analog
Inch-Metric:	Inch
Range:	0 - 1 "
Graduation:	0.0001"
Max. Permissible Error J MPE:	±0.0001"
Delivered:	Including box and spanner
Flatness:	0,000024"
Parallelism:	0.00008"
Measuring face:	Carbide-tipped, micro-lap finish
Measuring spindle:	With spindle lock, $\varnothing 6,35$ mm, spindle pitch 0,5 mm
Scale:	Thimble and sleeve satin chrome finish, $\varnothing 18$ mm
Measuring force:	5 - 15 N
Mass:	222 g

Dimensions

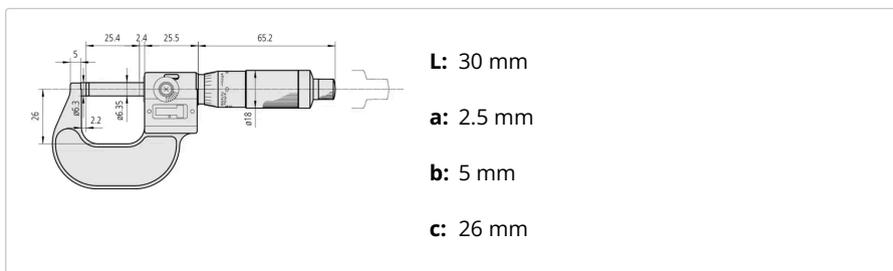

Accessories

Optional accessories:



Micrometer Stand, 45° Angle Type

for Micrometer 0-50mm/0-2"
Art No. 156-105-10
Suggested retail price: 58.00 €*
Suggested retail price: 58.00 €*
Suggested retail price: 58.00 €*

Promotion!



Micrometer Stand, Adjustable Angle Type

for Micrometer 0-100mm/0-4"
Art No. 156-101-10
Promo price: **56.00 €***
Suggested retail price: 70.00 €*
Suggested retail price: 70.00 €*
Suggested retail price: 70.00 €*