

Digit Outside Micrometer

Item number: 193-213

Images




Description

A Mitutoyo mechanical-digit micrometer with a vernier scale on the sleeve to provide high resolution. The highly stable frame incorporates a heat shield to preserve accuracy over extended measuring sessions. A ratchet stop guarantees repeatable measurement.

Features

Digital/Analog:	Analog
Inch-Metric:	Inch
Range:	2 - 3 "
Graduation:	0.0001"
Max. Permissible Error J MPE:	±0.0001"
Delivered:	Including box, setting standard, spanner
Flatness:	0,000024"
Parallelism:	0.00008"
Measuring face:	Carbide-tipped, micro-lap finish
Measuring spindle:	With spindle lock, $\varnothing 6,35$ mm, spindle pitch 0,5 mm
Scale:	Thimble and sleeve satin chrome finish, $\varnothing 18$ mm
Measuring force:	5 - 15 N
Mass:	379 g

Dimensions

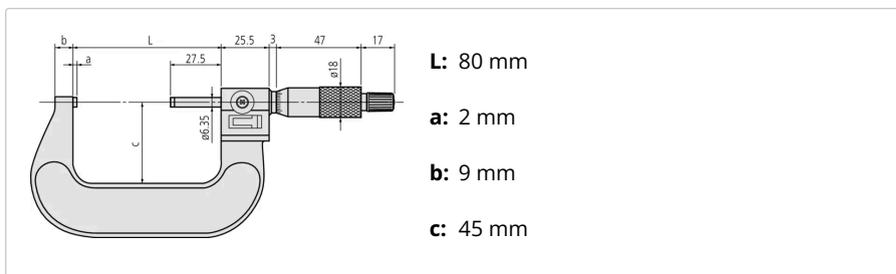

Accessories

Optional accessories:

Promotion!



Micrometer Stand, Adjustable Angle Type

for Micrometer 0-100mm/0-4"

Art No. 156-101-10

Promo price: **56.00 €***

Suggested retail price: ~~70.00 €*~~

Standard accessories:



Micrometer Setting Standard

Length: 2"

Art No. 167-142

Suggested retail price: 36.00 €*