


Micrometer Head Non-rotating Spindle

Item number: 197-101

Images

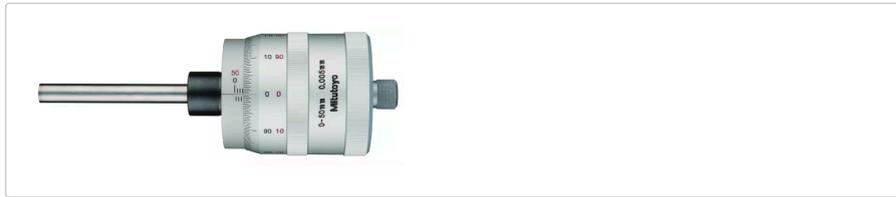

Description

A bidirectionally graduated large-thimble, rapid-feed non-digital Mitutoyo micrometer head with plain ± 18 mm stem and heavy-duty ± 8 mm non-rotating spindle fitted with flat tungsten-carbide tip.

Features

| | |
|---------------------------------------|--------------------------|
| Model: | MHQ-50 |
| Digital/Analog: | Analog |
| Inch-Metric: | Metric |
| Range: | 0 - 50 mm |
| Graduation: | 0.005 mm |
| Max. Permissible Error J MPE: | $\pm 5 \mu\text{m}$ |
| Spindle end: | Flat |
| Spindle pitch: | 1 mm |
| Stem \varnothing: | 18 mm |
| Stem: | Plain |
| Special features: | Bidirectional graduation |
| Measuring face: | Carbide tipped |
| Mass: | 300 g |

Dimensions

