


## Dial Snap Gauge without Indicator

Item number: 201-107

### Images

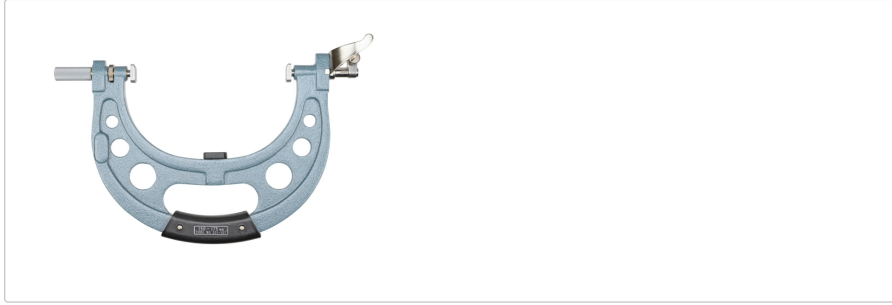

### Description

A Mitutoyo dial snap gauge designed for quick GO/NG judgement of diameters of cylinders and shafts. Anvils are chamfered for easy workpiece insertion. The dial indicator is optional, enabling the user to choose from the wide range available to best suit the application.

### Features

<b>Inch-Metric:</b>	Metric
<b>Range:</b>	150 - 175 mm
<b>Delivered:</b>	Including thermally insulating grip, workpiece stop
<b>Anvil retracting stroke:</b>	2 mm
<b>Repeatability:</b>	2 $\mu\text{m}$
<b>Flatness:</b>	1 $\mu\text{m}$
<b>Parallelism:</b>	5 $\mu\text{m}$
<b>Remarks:</b>	For indicator with 8 mm stem
<b>Measuring face:</b>	Carbide-tipped, micro-lap finish (13.5x12 mm)
<b>Measuring force:</b>	12 - 18 N
<b>Mass:</b>	1070 g

### Dimensions

### Accessories

Optional accessories:

Promotion!



### Dial Gauge, Flat Back, ISO Type

10mm, 0,01mm

Art No. 2046AB

Promo price: **38.00 €\***

Suggested retail price: ~~48.00 €\*~~

Promotion!



### Dial Gauge, Flat Back, ISO Type

Jewelled Bearing, Shockproof, 1mm, 0,001mm

Art No. 2109AB-10

Promo price: **84.00 €\***

Suggested retail price: ~~106.00 €\*~~



### Dial Gauge, Flat Back, ISO Type

One Revolution, Shock- & Dustproof, 1mm, 0,01mm

Art No. 2972AB

Suggested retail price: 72.00 €\*



### Protector for Indicator (plastic cover)

Art No. 21DZA000

Suggested retail price: 14.50 €\*

Standard accessories:



### Dial Indicator, Flat Back

10mm, 0,01mm  
Art No. 2046SB  
Suggested retail price: 34.00 €\*




### Dial Indicator, Flat Back

1mm, 0,001mm, Jeweled Bearing, Shockpr.  
Art No. 2109SB-10  
Suggested retail price: 89.00 €\*



### Protector for Indicator (plastic cover)

Art No. 21DZA000  
Suggested retail price: 14.50 €\*

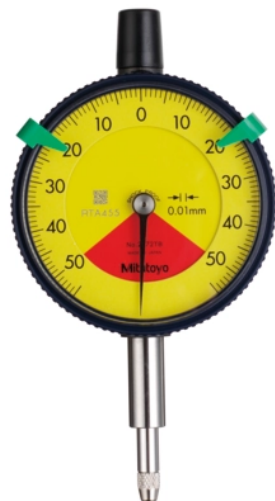

### Dial Indicator, Flat Back

1mm, 0,01mm, One Rev., Dust/Shockproof  
Art No. 2972TB  
Suggested retail price: 63.00 €\*