


Dial Snap Gauge without Indicator

Item number: 201-110

Images

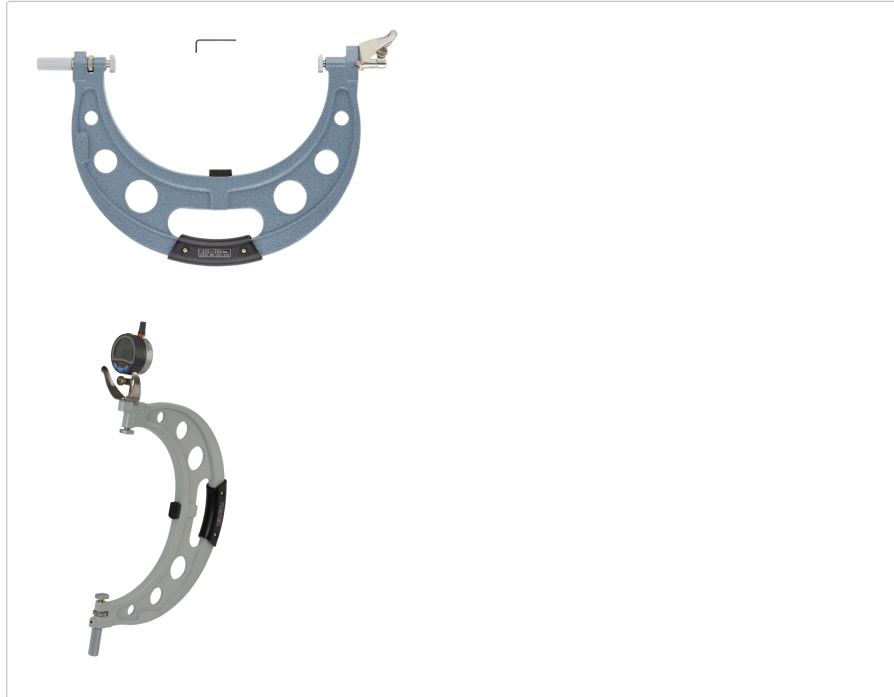

Description

A Mitutoyo dial snap gauge designed for quick GO/NG judgement of diameters of cylinders and shafts. Anvils are chamfered for easy workpiece insertion. The dial indicator is optional, enabling the user to choose from the wide range available to best suit the application.

Features

| | |
|---------------------------------|---|
| Delivered: | Including thermally insulating grip, workpiece stop |
| Inch-Metric: | Metric |
| Range: | 225 - 250 mm |
| Anvil retracting stroke: | 2 mm |
| Repeatability: | 2 μ m |
| Flatness: | 1 μ m |
| Parallelism: | 5 μ m |
| Remarks: | For indicator with 8 mm stem |
| Measuring face: | Carbide-tipped, micro-lap finish (13.5x12 mm) |
| Measuring force: | 12 - 18 N |
| Mass: | 1350 g |

Dimensions

Accessories

Optional accessories:

Promotion!



Dial Gauge, Flat Back, ISO Type

10mm, 0,01mm
Art No. 2046AB

Promo price: **37.90 €***
Suggested retail price: ~~48.00 €*~~



Dial Gauge, Flat Back, ISO Type

Jewelled Bearing, Shockproof, 1mm,
0,001mm
Art No. 2109AB-10

Suggested retail price: **106.00 €***



Dial Gauge, Flat Back, ISO Type

One Revolution, Shock- & Dustproof, 1mm,
0,01mm

Art No. 2972AB
Suggested retail price: **72.00 €***



Protector for Indicator (plastic cover)

Art No. 21DZA000
Suggested retail price: **20.00 €***

Standard accessories:



Dial Indicator, Flat Back

10mm, 0,01mm
Art No. 2046SB
Suggested retail price: 34.00 €*




Dial Indicator, Flat Back

1mm, 0,001mm, Jeweled Bearing, Shockpr.
Art No. 2109SB-10
Suggested retail price: 89.00 €*



Protector for Indicator (plastic cover)

Art No. 21DZA000
Suggested retail price: 20.00 €*

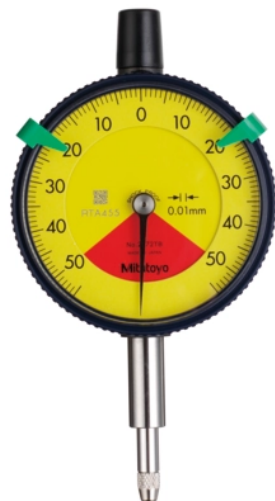

Dial Indicator, Flat Back

1mm, 0,01mm, One Rev., Dust/Shockproof
Art No. 2972TB
Suggested retail price: 63.00 €*