

Dial Snap Gauge without Indicator

Item number: 201-112

Images



Description

A Mitutoyo dial snap gauge designed for quick GO/NG judgement of diameters of cylinders and shafts. Anvils are chamfered for easy workpiece insertion. The dial indicator is optional, enabling the user to choose from the wide range available to best suit the application.

Features

Inch-Metric:	Metric
Range:	275 - 300 mm
Delivered:	Including thermally insulating grip, workpiece stop
Anvil retracting stroke:	2 mm
Repeatability:	2 μm
Flatness:	1 μm
Parallelism:	5 μm
Remarks:	For indicator with 8 mm stem
Measuring face:	Carbide-tipped, micro-lap finish (13.5x12 mm)
Measuring force:	12 - 18 N
Mass:	1620 g

Dimensions

Accessories

Optional accessories:

Promotion!



Dial Gauge, Flat Back, ISO Type

10mm, 0,01mm

Art No. 2046AB

Promo price: **38.00 €***

Suggested retail price: ~~48.00 €*~~

Promotion!



Dial Gauge, Flat Back, ISO Type

Jewelled Bearing, Shockproof, 1mm, 0,001mm

Art No. 2109AB-10

Promo price: **84.00 €***

Suggested retail price: ~~106.00 €*~~



Dial Gauge, Flat Back, ISO Type

One Revolution, Shock- & Dustproof, 1mm, 0,01mm

Art No. 2972AB

Suggested retail price: 72.00 €*



Protector for Indicator (plastic cover)

Art No. 21DZA000

Suggested retail price: 14.50 €*

Standard accessories:



Dial Indicator, Flat Back

10mm, 0,01mm
Art No. 2046SB
Suggested retail price: 34.00 €*




Dial Indicator, Flat Back

1mm, 0,001mm, Jeweled Bearing, Shockpr.
Art No. 2109SB-10
Suggested retail price: 89.00 €*



Protector for Indicator (plastic cover)

Art No. 21DZA000
Suggested retail price: 14.50 €*

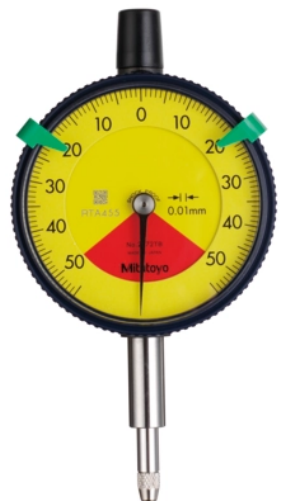

Dial Indicator, Flat Back

1mm, 0,01mm, One Rev., Dust/Shockproof
Art No. 2972TB
Suggested retail price: 63.00 €*