


External Digital Caliper Gauge

Item number: 209-932

Images

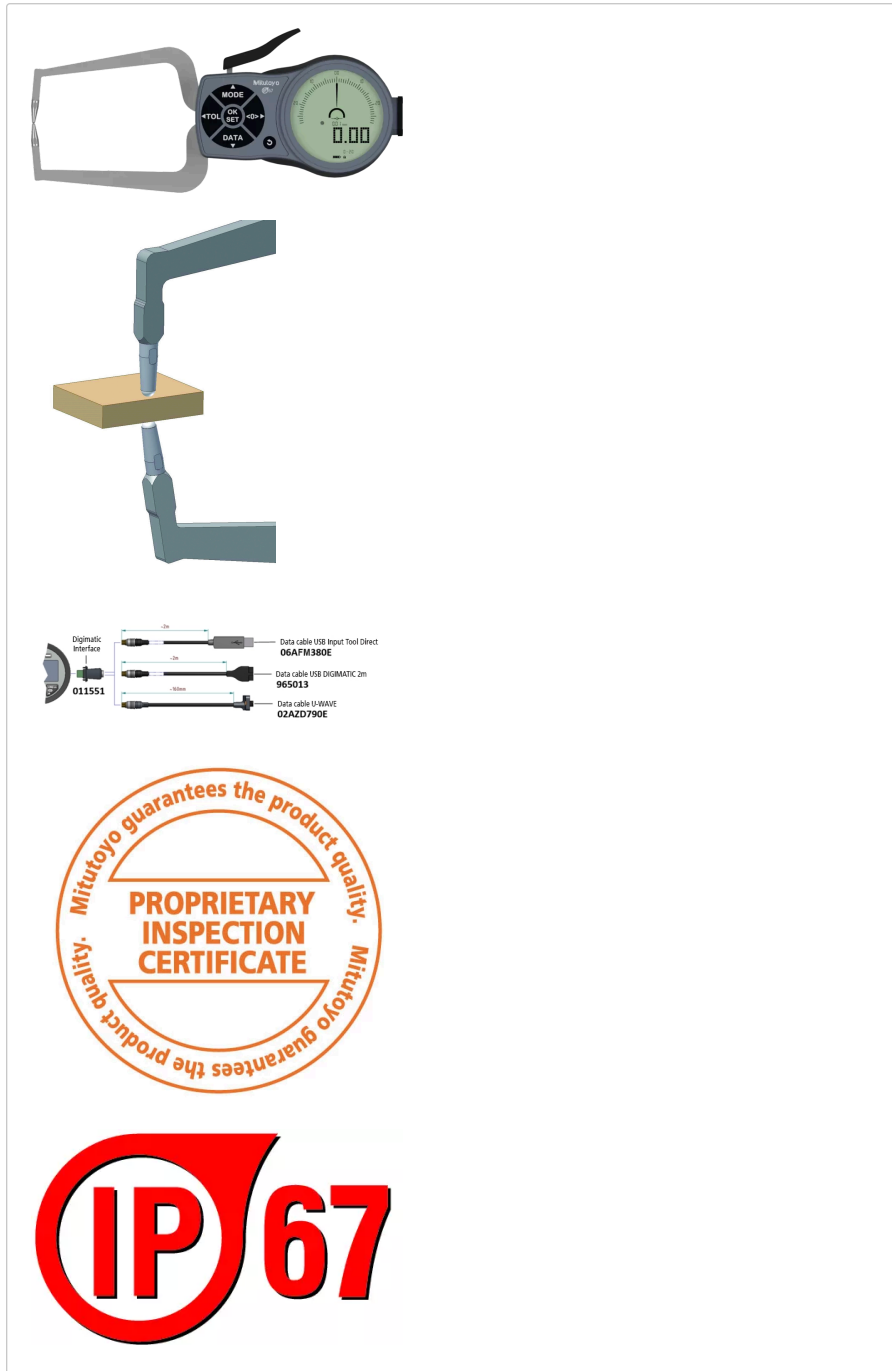

Description


- Digital Caliper Gauge enables measurements in hard-to-reach places
- Excellent resistance against water and dust IP67 level

Features


Digital/Analog:	Digital
Inch-Metric:	Metric/Inch
Delivered:	Including 2 batteries LR3, certificate of inspection
Range:	0 - 20 mm
Digital step:	0,001 / 0,002 / 0,005 / 0,01 / 0,02 / 0,05 mm
Protection:	IP67

Measuring force:	1,1-1,6 N
Mass:	270 g
Power supply:	2 batteries LR3 (AAA)
ABS/INC switchable:	Yes
Auto Power OFF after 1/5/10 min. non use:	YES
Analog bar resolution switchable:	Yes
OFFSET:	Yes
Type:	Fig. 1
Hb:	24.7 mm
Hf:	24.6 mm
mm/inch conversion:	Yes
HOLD:	Yes
SET key:	Yes
DATA key:	Yes
DATA-Logger (100 measured values):	Yes
Max. reading:	Yes
Min. reading:	Yes
Tolerance LED (green/red):	Yes
Tolerance judgement:	Yes

Dimensions

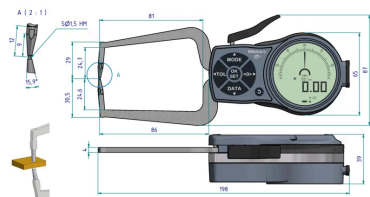

L: 81 mm

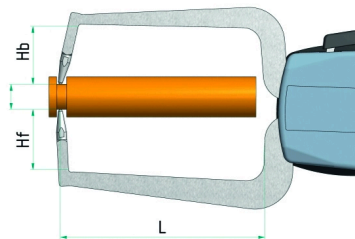

L: 81 mm

Accessories

Optional accessories:

Promotion!



U-WAVE-T, Buzzer Type

Wireless Transmitter

Art No. 02AZD880G

Promo price: **129.00 €***

Suggested retail price: ~~187.00 €*~~

Promotion!



Connection Cable E for U-WAVE

Round 6-Pin Type

Art No. 02AZD790E

Promo price: **63.90 €***

Suggested retail price: ~~98.00 €*~~

Promotion!




U-WAVE-R Wireless Receiver

Based on IEEE802.15.4 (2,4 GHz)

Art No. 02AZD810D

Promo price: **249.00 €***

Suggested retail price: ~~371.00 €*~~

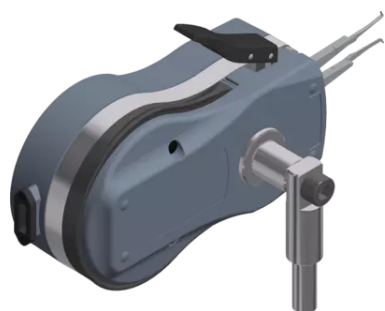

Holder for Digital Caliper Gauge

for 209-930 up to 209-958

Art No. 63AAA438

Suggested retail price: **189.00 €***

Spare parts

Consumable spares:



Battery LR03 (AAA)

4x

Art No. 011511-1

Price on application