 



## External Digital Caliper Gauge

Item number: 209-943

### Images

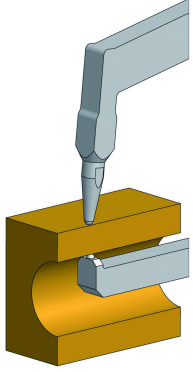

### Description

- Digital Caliper Gauge enables measurements in hard-to-reach places
- Excellent resistance against water and dust IP67 level

### Features

<b>Digital/Analog:</b>	Digital
<b>Inch-Metric:</b>	Metric/Inch
<b>Delivered:</b>	Including 2 batteries LR3, certificate of inspection
<b>Range:</b>	0 - 10 mm
<b>Digital step:</b>	0,001 / 0,002 / 0,005 / 0,01 / 0,02 / 0,05 mm





Promotion!



### U-WAVE-T, IP67 Type

Wireless Transmitter

Art No. 02AZD730G

Promo price: **129.00 €\***

Suggested retail price: ~~187.00 €\*~~

Promotion!




### Connection Cable E for U-WAVE

Round 6-Pin Type

Art No. 02AZD790E

Promo price: **63.90 €\***

Suggested retail price: ~~98.00 €\*~~

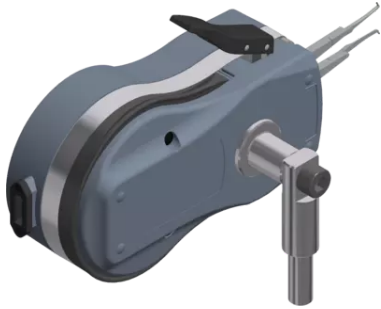

### Holder for Digital Caliper Gauge

for 209-930 up to 209-958

Art No. 63AAA438

Suggested retail price: **189.00 €\***



### Holder for Digital Caliper Gauge

for 209-901 up to 209-922

Art No. 63AAA437

Suggested retail price: **197.00 €\***

#### Spare parts

Consumable spares:



## Battery LR03 (AAA)

4x

Art No. 011511-1

Price on application