


35, 60, 90 Shore A Shore Hardness Reference Material Set

Item number: 218000MIT

Images

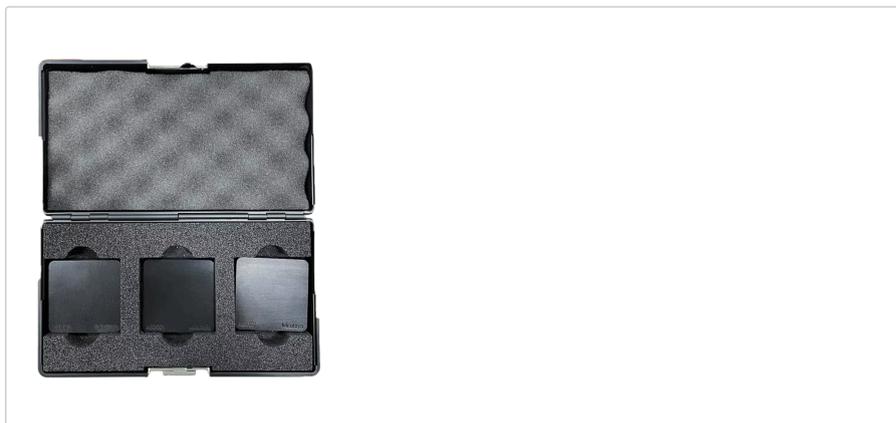

Description

Shore test specimen sets (3pcs.)

Please note:

- Recommended storage temperature: 23 °C ±5 °C
- Humidity 50 % ±15 %.

For best results, climate to laboratory conditions for min. 12 hours: 23 °C ±1 °C. Humidity 50 % ±10 %. Incorrect room temperature and humidity causes other readings. Annual recalibration of test specimen is recommended.

Shore test specimen should not be older than 2 years from initial calibration. Please replace after 2 years.

Please contact us if you do not find what you are looking for.

Features

Description:

Shore A test specimen set (3pcs.) with works calibration certificate according to ISO 48-4.

Test specimen for Durometer A
Dimension: 48mm x 48mm x 8mm
Nominal hardness: HA35, HA60, HA90
Color: black

Material: EPDM – longtime stable
Serial number engraved
Plastic case: L183mm x B110mm x H40mm
Please note:

Recommended storage temperature: 23 °C ±5 °C

Humidity 50 % ±15 %.

For best results, climate to laboratory conditions for min. 12 hours: 23 °C ±1 °C.

Humidity 50 % ±10 %.

Incorrect room temperature and humidity causes other readings. Annual recalibration of test specimen is recommended.

Method: Shore

Material: plastic

Hardness Value: 35, 60, 90

Scale 1: Shore A

Indenter:	Truncated cone indenter
------------------	-------------------------

Standard:	ISO 48-4
------------------	----------

Dimension:	48x48x8mm
-------------------	-----------

Net weight:	242 g
--------------------	-------

Product line:	<ul style="list-style-type: none">■ HH-331■ HH-332■ HH-335■ HH-336
----------------------	---