


Absolute Digital Mic., Adjust. Force

Item number: 227-201-20

Images

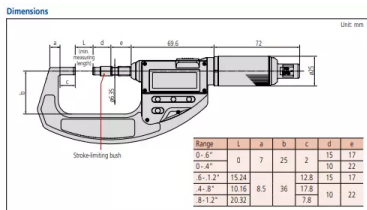

ABSOLUTE®

Description

This Quickmike has an adjustable measuring force to suit various kinds of workpieces.

The ABSOLUTE Digimatic Micrometer Quickmike offers the following benefits:

- It's dedicated to applications requiring a constant/low measuring force such as measuring wire, paper and plastic/rubber parts.
- Constant and low measuring force mechanism in the thimble.
- Non-rotating spindle.
- Speedy spindle feed of 10 mm per thimble rotation.

Features

Model: CLM1-15QMX

Digital/Analog: Digital


Inch-Metric: Metric

Range: 0 - 15 mm

Digital step: 0.001 mm

Max. Permissible Error J MPE:	±2 µm
Delivered:	Including box, screwdriver, 1 SR44 battery
Flatness:	0.3 µm
Parallelism:	2 µm
Display:	LCD, character height 10 mm
Measuring face:	Carbide-tipped, micro-lap finish
Measuring spindle:	ø6.35 mm, non-rotating, spindle feed 10 mm
Data output:	Yes
Measuring force settings:	0.5; 1; 1.5; 2; 2.5 N
Measuring force accuracy ⁽¹⁾:	±0.1 + (force setting/10) N
Power supply:	1 battery SR-44
Battery life:	Approx. 5 years
ON/OFF:	Yes
ABS / INC (INC ZERO):	Yes
Low voltage alarm:	Yes
Function lock:	Yes
HOLD:	Yes
PRESET:	Yes
Mass:	300 g

Dimensions

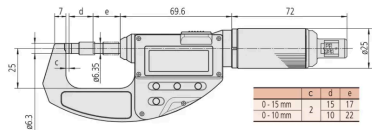

Accessories

Optional accessories:



Micrometer Stand, 45° Angle Type

for Micrometer 0-50mm/0-2"
 Art No. 156-105-10
 Suggested retail price: 58.00 €*

Promotion!



Micrometer Stand, Adjustable Angle Type

for Micrometer 0-100mm/0-4"

Art No. 156-101-10

Promo price: **56.00 €***

Suggested retail price: ~~70.00 €*~~

Promotion!



Connection Cable B for U-WAVE

with Data Button for IP Micrometer Type

Art No. 02AZD790B

Promo price: **76.00 €***

Suggested retail price: ~~110.00 €*~~

Promotion!



USB Input Tool Direct (Digimatic to USB)

2m Cable, Digimatic/Digimatic 2, with Data Button IP Micrometer Type

Art No. 06AFM380B

Promo price: **111.00 €***

Suggested retail price: ~~141.00 €*~~



Digimatic Cable with Data Button IP Type

1 m, Micrometer Type

Art No. 05CZA662

Suggested retail price: **105.00 €***



Digimatic Cable with Data Button IP Type

2 m, Micrometer Type

Art No. 05CZA663

Suggested retail price: **107.00 €***

Promotion!



U-WAVE-T, IP67 Type

Wireless Transmitter

Art No. 02AZD730G

Promo price: **129.00 €***

Suggested retail price: ~~187.00 €*~~

Promotion!



U-WAVE-T, Buzzer Type

Wireless Transmitter

Art No. 02AZD880G

Promo price: **129.00 €***

Suggested retail price: ~~187.00 €*~~

Promotion!

Mitutoyo

MICAT

the standard in world
metrology software
measurLink

USB-ITPAK Vers. 3.0

USB Dongle + Manual (Software available
Online)

Art No. 06AGR543

Promo price: **268.00 €***

Suggested retail price: ~~340.00 €*~~



USB-ITPAK

Spare parts

Consumable spares:



Battery SR44 1,5 V

Art No. 938882

Suggested retail price: 7.00 €*