


Absolute Digital Mic., Adjust. Force

Item number: 227-206-20

Images

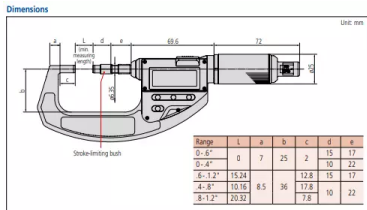

ABSOLUTE®

Description

This Quickmike has an adjustable measuring force to suit various kinds of workpieces.

The ABSOLUTE Digimatic Micrometer Quickmike offers the following benefits:


- It's dedicated to applications requiring a constant/low measuring force such as measuring wire, paper and plastic/rubber parts.
- Constant and low measuring force mechanism in the thimble.
- Non-rotating spindle.
- Speedy spindle feed of 10 mm per thimble rotation.

Features

Model:	CLM2-20QMX
Digital/Analog:	Digital
Delivered:	Including box, setting standard, screwdriver, 1 SR44 battery

Inch-Metric:	Metric
Range:	10 - 20 mm
Digital step:	0.001 mm
Max. Permissible Error J MPE:	$\pm 2 \mu\text{m}$
Flatness:	$0.3 \mu\text{m}$
Parallelism:	$2 \mu\text{m}$
Display:	LCD, character height 10 mm
Measuring face:	Carbide-tipped, micro-lap finish
Measuring spindle:	$\varnothing 6.35$ mm, non-rotating, spindle feed 10 mm
Measuring force settings:	2; 4; 6; 8; 10 N
Measuring force accuracy ⁽¹⁾:	$\pm 0.4 + (\text{force setting}/10)$ N
Power supply:	1 battery SR-44
Battery life:	Approx. 5 years
ON/OFF:	Yes
ABS / INC (INC ZERO):	Yes
Low voltage alarm:	Yes
Function lock:	Yes
HOLD:	Yes
PRESET:	Yes
Mass:	425 g

Dimensions

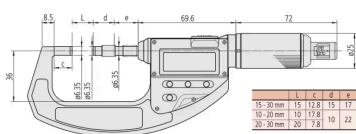

Promotion!



Micrometer Stand, Adjustable Angle Type

for Micrometer 0-100mm/0-4"

Art No. 156-101-10

Promo price: **55.90 €***

Suggested retail price: ~~70.00 €*~~

Promotion!



Connection Cable B for U-WAVE

with Data Button for IP Micrometer Type

Art No. 02AZD790B

Promo price: **72.90 €***

Suggested retail price: ~~110.00 €*~~

Promotion!



USB Input Tool Direct (Digimatic to USB)

2m Cable, Digimatic/Digimatic 2, with Data Button IP Micrometer Type

Art No. 06AFM380B

Promo price: **109.00 €***

Suggested retail price: ~~141.00 €*~~



Digimatic Cable with Data Button IP Type

1m, Micrometer Type

Art No. 05CZA662

Suggested retail price: **105.00 €***



Digimatic Cable with Data Button IP Type

2m, Micrometer Type

Art No. 05CZA663

Suggested retail price: **107.00 €***

Promotion!



U-WAVE-T, IP67 Type

Wireless Transmitter
Art No. 02AZD730G
Promo price: **129.00 €***
Suggested retail price: ~~187.00 €*~~

Promotion!



U-WAVE-T, Buzzer Type

Wireless Transmitter
Art No. 02AZD880G
Promo price: **129.00 €***
Suggested retail price: ~~187.00 €*~~

Promotion!

Mitutoyo

MiCAT
the standard in world
metrology software
measurLink

USB-ITPAK Vers. 3.0

USB Dongle + Manual (Software available
Online)
Art No. 06AGR543
Promo price: **259.00 €***
Suggested retail price: ~~340.00 €*~~



Standard accessories:

Micrometer Setting Standard

Length: 25mm
Art No. 167-101
Suggested retail price: 33.00 €*



Spare parts

Consumable spares:



Battery SR44 1,5 V

Art No. 938882

Suggested retail price: 10.00 €*
