


Absolute Digital Mic., Adjust. Force

Item number: 227-207-20

Images

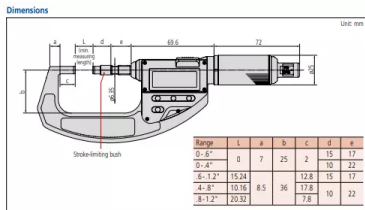

ABSOLUTE®

Description

This Quickmike has an adjustable measuring force to suit various kinds of workpieces.

The ABSOLUTE Digimatic Micrometer Quickmike offers the following benefits:

- It's dedicated to applications requiring a constant/low measuring force such as measuring wire, paper and plastic/rubber parts.
- Constant and low measuring force mechanism in the thimble.
- Non-rotating spindle.
- Speedy spindle feed of 10 mm per thimble rotation.

Features


Model: CLM2-30QMX

Digital/Analog: Digital

Delivered: Including box, setting standard, screwdriver, 1 SR44 battery

| | |
|---|---|
| Inch-Metric: | Metric |
| Range: | 20 - 30 mm |
| Digital step: | 0.001 mm |
| Max. Permissible Error J MPE: | $\pm 2 \mu\text{m}$ |
| Flatness: | $0.3 \mu\text{m}$ |
| Parallelism: | $2 \mu\text{m}$ |
| Display: | LCD, character height 10 mm |
| Measuring face: | Carbide-tipped, micro-lap finish |
| Measuring spindle: | $\varnothing 6.35$ mm, non-rotating, spindle feed 10 mm |
| Measuring force settings: | 2; 4; 6; 8; 10 N |
| Measuring force accuracy ⁽¹⁾: | $\pm 0.4 + (\text{force setting}/10)$ N |
| Power supply: | 1 battery SR-44 |
| Battery life: | Approx. 5 years |
| ON/OFF: | Yes |
| ABS / INC (INC ZERO): | Yes |
| Low voltage alarm: | Yes |
| Function lock: | Yes |
| HOLD: | Yes |
| PRESET: | Yes |
| Mass: | 415 g |

Dimensions

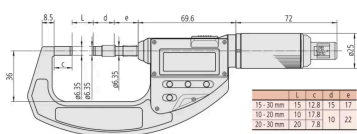

Accessories

Optional accessories:



Micrometer Stand, 45° Angle Type

for Micrometer 0-50mm/0-2"

Art No. 156-105-10

Suggested retail price: 58.00 €*

Promotion!



Micrometer Stand, Adjustable Angle Type

for Micrometer 0-100mm/0-4"

Art No. 156-101-10

Promo price: **55.90 €***

Suggested retail price: ~~70.00 €*~~

Promotion!



Connection Cable B for U-WAVE

with Data Button for IP Micrometer Type

Art No. 02AZD790B

Promo price: **72.90 €***

Suggested retail price: ~~110.00 €*~~

Promotion!



USB Input Tool Direct (Digimatic to USB)

2m Cable, Digimatic/Digimatic 2, with Data Button IP Micrometer Type

Art No. 06AFM380B

Promo price: **109.00 €***

Suggested retail price: ~~141.00 €*~~



Digimatic Cable with Data Button IP Type

1m, Micrometer Type

Art No. 05CZA662

Suggested retail price: **105.00 €***



Digimatic Cable with Data Button IP Type

2m, Micrometer Type

Art No. 05CZA663

Suggested retail price: **107.00 €***

Promotion!



U-WAVE-T, IP67 Type

Wireless Transmitter
Art No. 02AZD730G
Promo price: **129.00 €***
Suggested retail price: ~~187.00 €*~~

Promotion!



U-WAVE-T, Buzzer Type

Wireless Transmitter
Art No. 02AZD880G
Promo price: **129.00 €***
Suggested retail price: ~~187.00 €*~~

Promotion!

Mitutoyo

MiCAT
the standard in world
metrology software
measurLink

USB-ITPAK Vers. 3.0

USB Dongle + Manual (Software available
Online)
Art No. 06AGR543
Promo price: **259.00 €***
Suggested retail price: ~~340.00 €*~~



Standard accessories:

Micrometer Setting Standard

Length: 25mm
Art No. 167-101
Suggested retail price: 33.00 €*



Spare parts

Consumable spares:



Battery SR44 1,5 V

Art No. 938882

Suggested retail price: 10.00 €*
