


# Absolute Digital Mic., Adjust. Force

Item number: 227-216-20

## Images

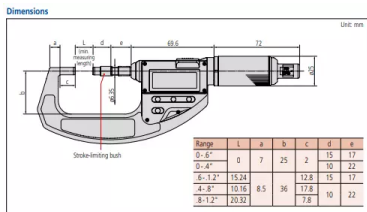

# ABSOLUTE®

## Description

This Quickmike has an adjustable measuring force to suit various kinds of workpieces.

The ABSOLUTE Digimatic Micrometer Quickmike offers the following benefits:

- It's dedicated to applications requiring a constant/low measuring force such as measuring wire, paper and plastic/rubber parts.
- Constant and low measuring force mechanism in the thimble.
- Non-rotating spindle.
- Speedy spindle feed of 10 mm per thimble rotation.

## Features

<b>Model:</b>	CLM2-.8"QMX
<b>Digital/Analog:</b>	Digital
<b>Delivered:</b>	Including box, setting standard, screwdriver, 1 SR44 battery
<b>Inch-Metric:</b>	Inch/Metric
<b>Range:</b>	0.4 - 0.8 "

<b>Digital step:</b>	0.00005"/0.001 mm
<b>Max. Permissible Error J MPE:</b>	±0.0001"
<b>Flatness:</b>	0.000012"
<b>Parallelism:</b>	0.00008"
<b>Display:</b>	LCD, character height 10 mm
<b>Measuring face:</b>	Carbide-tipped, micro-lap finish
<b>Measuring spindle:</b>	ø6.35 mm, non-rotating, spindle feed 10 mm
<b>Measuring force settings:</b>	2; 4; 6; 8; 10 N
<b>Measuring force accuracy <sup>(1)</sup>:</b>	±0.4 + (force setting/10) N
<b>Power supply:</b>	1 battery SR-44
<b>Battery life:</b>	Approx. 5 years
<b>ON/OFF:</b>	Yes
<b>ABS / INC (INC ZERO):</b>	Yes
<b>Low voltage alarm:</b>	Yes
<b>Function lock:</b>	Yes
<b>HOLD:</b>	Yes
<b>PRESET:</b>	Yes
<b>Mass:</b>	425 g

## Accessories

### Optional accessories:



### Micrometer Stand, 45° Angle Type

for Micrometer 0-50mm/0-2"  
 Art No. 156-105-10  
 Suggested retail price: 58.00 €\*

Promotion!



### Micrometer Stand, Adjustable Angle Type

for Micrometer 0-100mm/0-4"  
 Art No. 156-101-10  
 Promo price: **55.90 €\***   
 Suggested retail price: 70.00 €\*

Promotion!



### Connection Cable B for U-WAVE

with Data Button for IP Micrometer Type

Art No. 02AZD790B

Promo price: **72.90 €\***

Suggested retail price: ~~110.00 €\*~~

Promotion!



### USB Input Tool Direct (Digimatic to USB)

2m Cable, Digimatic/Digimatic 2, with Data Button IP Micrometer Type

Art No. 06AFM380B

Promo price: **109.00 €\***

Suggested retail price: ~~141.00 €\*~~

### Digimatic Cable with Data Button IP Type



1m, Micrometer Type

Art No. 05CZA662

Suggested retail price: **105.00 €\***

### Digimatic Cable with Data Button IP Type



2m, Micrometer Type

Art No. 05CZA663

Suggested retail price: **107.00 €\***

Promotion!



### U-WAVE-T, IP67 Type

Wireless Transmitter

Art No. 02AZD730G

Promo price: **129.00 €\***

Suggested retail price: ~~187.00 €\*~~

Promotion!



## U-WAVE-T, Buzzer Type

Wireless Transmitter

Art No. 02AZD880G

Promo price: **129.00 €\***

Suggested retail price: ~~187.00 €\*~~

Promotion!

Mitutoyo

MiCAT

the standard in world  
metrology software  
MeasurLink

## USB-ITPAK Vers. 3.0

USB Dongle + Manual (Software available  
Online)


Art No. 06AGR543

Promo price: **259.00 €\***

Suggested retail price: ~~340.00 €\*~~

USB-ITPAK

Standard accessories:

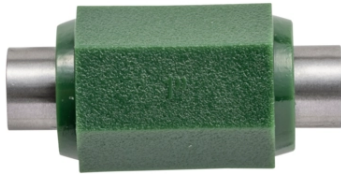

## Micrometer Setting Standard

Length: 1"

Art No. 167-141

Suggested retail price: **33.00 €\***

Spare parts

Consumable spares:



## Battery SR44 1,5 V

Art No. 938882

Suggested retail price: **10.00 €\***

