


Absolute Digital Mic., Adjust. Force

Item number: 227-217-20

Images

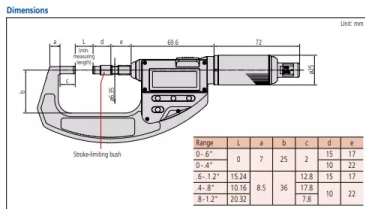

ABSOLUTE®

Description

This Quickmike has an adjustable measuring force to suit various kinds of workpieces.

The ABSOLUTE Digimatic Micrometer Quickmike offers the following benefits:

- It's dedicated to applications requiring a constant/low measuring force such as measuring wire, paper and plastic/rubber parts.
- Constant and low measuring force mechanism in the thimble.
- Non-rotating spindle.
- Speedy spindle feed of 10 mm per thimble rotation.

Features

| | |
|------------------------|--|
| Model: | CLM2-1.2"QMX |
| Digital/Analog: | Digital |
| Delivered: | Including box, setting standard, screwdriver, 1 SR44 battery |
| Inch-Metric: | Inch/Metric |
| Range: | 0.8 - 1.2 " |

| | |
|---|--|
| Digital step: | 0.00005"/0.001 mm |
| Max. Permissible Error J MPE: | ±0.0001" |
| Flatness: | 0.000012" |
| Parallelism: | 0.00008" |
| Display: | LCD, character height 10 mm |
| Measuring face: | Carbide-tipped, micro-lap finish |
| Measuring spindle: | ø6.35 mm, non-rotating, spindle feed 10 mm |
| Measuring force settings: | 2; 4; 6; 8; 10 N |
| Measuring force accuracy ⁽¹⁾: | ±0.4 + (force setting/10) N |
| Power supply: | 1 battery SR-44 |
| Battery life: | Approx. 5 years |
| ON/OFF: | Yes |
| ABS / INC (INC ZERO): | Yes |
| Low voltage alarm: | Yes |
| Function lock: | Yes |
| HOLD: | Yes |
| PRESET: | Yes |
| Mass: | 415 g |

Accessories

Optional accessories:



Micrometer Stand, 45° Angle Type

for Micrometer 0-50mm/0-2"
 Art No. 156-105-10
 Suggested retail price: 58.00 €*

Promotion!



Micrometer Stand, Adjustable Angle Type

for Micrometer 0-100mm/0-4"
 Art No. 156-101-10
 Promo price: **55.90 €***
 Suggested retail price: 70.00 €*

Promotion!



Connection Cable B for U-WAVE

with Data Button for IP Micrometer Type

Art No. 02AZD790B

Promo price: **72.90 €***

Suggested retail price: ~~110.00 €*~~

Promotion!



USB Input Tool Direct (Digimatic to USB)

2m Cable, Digimatic/Digimatic 2, with Data Button IP Micrometer Type

Art No. 06AFM380B

Promo price: **109.00 €***

Suggested retail price: ~~141.00 €*~~

Digimatic Cable with Data Button IP Type



1m, Micrometer Type

Art No. 05CZA662

Suggested retail price: 105.00 €*

Digimatic Cable with Data Button IP Type



2m, Micrometer Type

Art No. 05CZA663

Suggested retail price: 107.00 €*

Promotion!



U-WAVE-T, IP67 Type

Wireless Transmitter

Art No. 02AZD730G

Promo price: **129.00 €***

Suggested retail price: ~~187.00 €*~~

Promotion!



U-WAVE-T, Buzzer Type

Wireless Transmitter

Art No. 02AZD880G

Promo price: **129.00 €***

Suggested retail price: ~~187.00 €*~~

Promotion!

Mitutoyo

MiCAT

the standard in world
metrology software
MeasurLink®

USB-ITPAK Vers. 3.0

USB Dongle + Manual (Software available
Online)

Art No. 06AGR543

Promo price: **259.00 €***

Suggested retail price: ~~340.00 €*~~

USB-ITPAK

Standard accessories:



Micrometer Setting Standard

Length: 1"

Art No. 167-141

Suggested retail price: **33.00 €***

Spare parts

Consumable spares:



Battery SR44 1,5 V

Art No. 938882

Suggested retail price: **10.00 €***

