


Digital Micrometer IP65

Item number: 293-234-30

Images

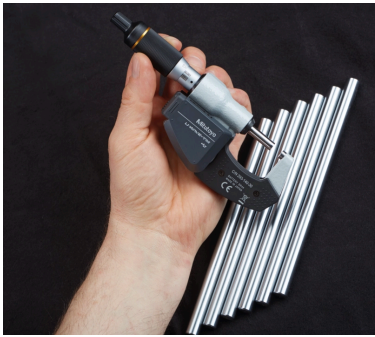

Dust- and
Water-
Protected

www.tuv.com
ID 0000040191

Description

This IP65 micrometer offers outstanding accuracy, with data output, is highly robust and offers the following benefits:


- Oil-resistant material used for all plastic parts
- Extraordinary battery life of 2,4 years
- Excellent resistance against water and dust enables this micrometer to be used in machining situations that include splashing coolant fluid.

Features

Model:	MDC-25MXT
Digital/Analog:	Digital
Delivered:	Including box, spanner, SR44 battery, certificate of inspection

Inch-Metric:	Metric
Range:	0 - 25 mm
Digital step:	0,001 mm
Max. Permissible Error J MPE:	±1 µm
Flatness:	0,3 µm
Parallelism:	1 µm
Data output:	Yes
Display:	LCD, character height 7,5 mm
Measuring face:	Carbide-tipped, micro-lap finish
Measuring spindle:	With spindle lock, ø6,35 mm, spindle pitch 0,5 mm
Scale:	Thimble and sleeve satin chrome finish, ø18 mm
Measuring force:	5 - 10 N
Power supply:	1 battery SR-44
Battery life:	Approx. 2.4 years for models ≤100 mm 1.2 years for >100 mm
ABS / INC (INC ZERO):	Yes
Auto Power OFF after 20 min. non use:	Yes
Low voltage alarm:	Yes
Function lock:	Yes
HOLD:	Yes
2 x PRESET (over 100 mm):	Yes
Mass:	270 g

Dimensions

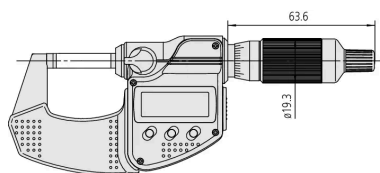

- L:** 0 mm
- a:** 6.5 mm
- b:** 25 mm
- c:** 2.5 mm

Accessories

Proposed additional product:

Promotion!



Connection Unit for IP Caliper, Micrometer

with Data Button for U-WAVE fit, U-WAVE fit Bluetooth

Art No. 02AZF310

Promo price: **74.90 €***

Suggested retail price: ~~110.00 €*~~

Promotion!



U-WAVE fit, Buzzer Type

Wireless Transmitter for Micrometer/Indicator

Art No. 264-623

Promo price: **129.00 €***

Suggested retail price: ~~185.00 €*~~



Digimatic Cable with Data Button IP Type

1m, Micrometer Type

Art No. 05CZA662

Suggested retail price: ~~105.00 €*~~



Digimatic Cable with Data Button IP Type

2m, Micrometer Type

Art No. 05CZA663

Suggested retail price: ~~107.00 €*~~

Promotion!



USB Input Tool Direct (Digimatic to USB)

2m Cable, Digimatic/Digimatic 2, with Data Button IP Micrometer Type

Art No. 06AFM380B

Promo price: **109.00 €***

Suggested retail price: ~~141.00 €*~~

Promotion!



U-WAVE fit, IP67 Type

Wireless Transmitter for
Micrometer/Indicator
Art No. 264-622

Promo price: **129.00 €***
Suggested retail price: ~~185.00 €*~~

Optional accessories:



Micrometer Stand, 45° Angle Type

for Micrometer 0-50mm/0-2"
Art No. 156-105-10
Suggested retail price: **58.00 €***

Promotion!



Micrometer Stand, Adjustable Angle Type

for Micrometer 0-100mm/0-4"
Art No. 156-101-10
Promo price: **55.90 €***
Suggested retail price: ~~70.00 €*~~

Promotion!



Connection Unit for IP Caliper, Micrometer

with Data Button for U-WAVE fit, U-WAVE fit
Bluetooth
Art No. 02AZF310
Promo price: **74.90 €***
Suggested retail price: ~~110.00 €*~~

Promotion!



USB Input Tool Direct (Digimatic to USB)

2m Cable, Digimatic/Digimatic 2, with Data
Button IP Micrometer Type
Art No. 06AFM380B
Promo price: **109.00 €***
Suggested retail price: ~~141.00 €*~~



Digimatic Cable with Data Button IP Type

1m, Micrometer Type
Art No. 05CZA662
Suggested retail price: 105.00 €*



Digimatic Cable with Data Button IP Type

2m, Micrometer Type
Art No. 05CZA663
Suggested retail price: 107.00 €*

Promotion!



U-WAVE fit, IP67 Type

Wireless Transmitter for
Micrometer/Indicator
Art No. 264-622
**Promo price: 129.00 €*
Suggested retail price: 185.00 €*

---**

Promotion!



U-WAVE fit, Buzzer Type

Wireless Transmitter for
Micrometer/Indicator
Art No. 264-623
**Promo price: 129.00 €*
Suggested retail price: 185.00 €*

---**

Promotion!



U-WAVE fit Bluetooth, IP67 Type

Wireless Transmitter for
Micrometer/Indicator
Art No. 264-626
**Promo price: 139.00 €*
Suggested retail price: 185.00 €*

---**

Promotion!



U-WAVE fit Bluetooth, Buzzer Type

Wireless Transmitter for
Micrometer/Indicator
Art No. 264-627

Promo price: **139.00 €***
~~Suggested retail price: 185.00 €*~~

Promotion!

Mitutoyo

MiCAT

the standard in world
metrology software
MeasurLink™

USB-ITPAK Vers. 3.0

USB Dongle + Manual (Software available
Online)

Art No. 06AGR543

Promo price: **259.00 €***
~~Suggested retail price: 340.00 €*~~



Spare parts

Consumable spares:



Battery SR44 1,5 V

Art No. 938882
Suggested retail price: 10.00 €*