

Digital Micrometer IP65

Item number: 293-241-30

Images



Dust- and
Water-
Protected

www.tuv.com
ID 0000040191

Description

This IP65 micrometer offers outstanding accuracy, without data output, is highly robust and offers the following benefits:


- Oil-resistant material used for all plastic parts
- Extraordinary battery life of 2,4 years
- Excellent resistance against water and dust enables this micrometer to be used in machining situations that include splashing coolant fluid.

Features

Model:	MDC-50PX
Digital/Analog:	Digital
Inch-Metric:	Metric
Range:	25 - 50 mm
Digital step:	0.001 mm
Max. Permissible Error J MPE:	±1 µm
Delivered:	Including box, spanner, SR44 battery, setting standard, certificate of inspection
Flatness:	0.3 µm
Parallelism:	1 µm
Display:	LCD, character height 7.5 mm
Measuring face:	Carbide-tipped, micro-lap finish
Measuring spindle:	With spindle lock, ø6.35 mm, spindle pitch 0.5 mm

Scale:	Thimble and sleeve satin chrome finish, ø18 mm
Data output:	No
Measuring force:	5 - 10 N
Power supply:	1 battery SR-44
Battery life:	Approx. 2.4 years for models ≤100 mm 1.2 years for > 100 mm
ABS / INC (INC ZERO):	Yes
Auto Power OFF after 20 min. non use:	Yes
Low voltage alarm:	Yes
Function lock:	Yes
HOLD:	Yes
Mass:	330 g

Dimensions

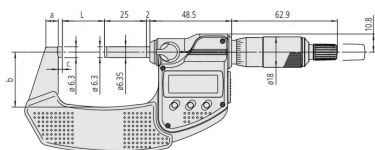

L: 25 mm

a: 7.3 mm

b: 32.5 mm

c: 2.5 mm

Accessories

Optional accessories:



Micrometer Stand, 45° Angle Type

for Micrometer 0-50mm/0-2"
Art No. 156-105-10
Suggested retail price: 58.00 €*

Promotion!



Micrometer Stand, Adjustable Angle Type

for Micrometer 0-100mm/0-4"
Art No. 156-101-10
Promo price: 56.00 €*
Suggested retail price: 70.00 €*

Standard accessories:

Micrometer Setting Standard



Length: 25mm
Art No. 167-101
Suggested retail price: 33.00 €*

Spare parts

Consumable spares:



Battery SR44 1,5 V

Art No. 938882
Suggested retail price: 7.00 €*
