

## Digital Micrometer IP65

Item number: 293-243-30

### Images



Dust- and  
Water-  
Protected

www.tuv.com  
ID 0000040191

### Description

This IP65 micrometer offers outstanding accuracy, without data output, is highly robust and offers the following benefits:


- Oil-resistant material used for all plastic parts
- Extraordinary battery life of 2,4 years
- Excellent resistance against water and dust enables this micrometer to be used in machining situations that include splashing coolant fluid.

### Features

<b>Model:</b>	MDC-100PX
<b>Digital/Analog:</b>	Digital
<b>Inch-Metric:</b>	Metric
<b>Range:</b>	75 - 100 mm
<b>Digital step:</b>	0.001 mm
<b>Max. Permissible Error J MPE:</b>	±2 µm
<b>Delivered:</b>	Including box, spanner, SR44 battery, setting standard
<b>Flatness:</b>	0.3 µm
<b>Parallelism:</b>	2 µm
<b>Display:</b>	LCD, character height 7.5 mm
<b>Measuring face:</b>	Carbide-tipped, micro-lap finish
<b>Measuring spindle:</b>	With spindle lock, ø6.35 mm, spindle pitch 0.5 mm

<b>Scale:</b>	Thimble and sleeve satin chrome finish, ø18 mm
<b>Data output:</b>	No
<b>Measuring force:</b>	5 - 10 N
<b>Power supply:</b>	1 battery SR-44
<b>Battery life:</b>	Approx. 2.4 years for models ≤100 mm 1.2 years for > 100 mm
<b>ABS / INC (INC ZERO):</b>	Yes
<b>Auto Power OFF after 20 min. non use:</b>	Yes
<b>Low voltage alarm:</b>	Yes
<b>Function lock:</b>	Yes
<b>HOLD:</b>	Yes
<b>Mass:</b>	625 g

## Dimensions

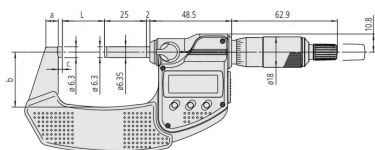

**L:** 75 mm

**a:** 11.5 mm

**b:** 60 mm

**c:** 2.5 mm

## Accessories

### Optional accessories:

**Micrometer Stand, Adjustable Angle Type**

for Micrometer 0-100mm/0-4"  
Art No. 156-101-10

**Promo price: 56.00 €\***   
~~Suggested retail price: 70.00 €\*~~

### Standard accessories:



### Micrometer Setting Standard

Length: 75mm

Art No. 167-103

Suggested retail price: 37.00 €\*

**Spare parts**

Consumable spares:

---



**Battery SR44 1,5 V**

Art No. 938882

Suggested retail price: 7.00 €\*  

---