

Digital Micrometer IP65, Inch/Metric

Item number: 293-345-30

Images




Description

A Mitutoyo waterproof digital micrometer suitable for use in the presence of coolant or cutting oil. The highly stable frame incorporates a heat shield to preserve accuracy over extended measuring sessions. A ratchet thimble guarantees repeatable measurement.

Features

Model:	MDC-2"PXT
Digital/Analog:	Digital
Inch-Metric:	Inch/Metric
Range:	1 - 2 "
Digital step:	0.00005"/0.001 mm
Max. Permissible Error J MPE:	±0.00005"
Delivered:	Including box, spanner, SR44 battery, setting standard, certificate of inspection
Flatness:	0.000012"
Parallelism:	0.00004"
Display:	LCD, character height 7.5 mm
Measuring face:	Carbide-tipped, micro-lap finish
Measuring spindle:	With spindle lock, $\varnothing 6,35$ mm, spindle pitch 0,5 mm
Scale:	Thimble and sleeve satin chrome finish, $\varnothing 18$ mm
Data output:	No
Measuring force:	7 - 12 N
Power supply:	1 battery SR-44
Battery life:	Approx. 2.4 years for models ≤ 4 " 1.2 years for > 4 "
ABS / INC (INC ZERO):	Yes
Auto Power OFF after 20 min. non use:	Yes
Low voltage alarm:	Yes
Function lock:	Yes
HOLD:	Yes
2 x PRESET (over 100 mm):	Yes
Mass:	340 g

Dimensions

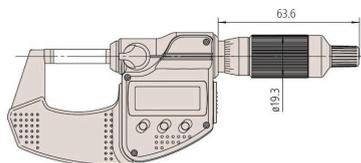

L: 25 mm

a: 7.3 mm

b: 32.5 mm

c: 2.5 mm

Accessories

Optional accessories:

