


Digital Micrometer IP65, Inch/Metric

Item number: 293-346-30

Images

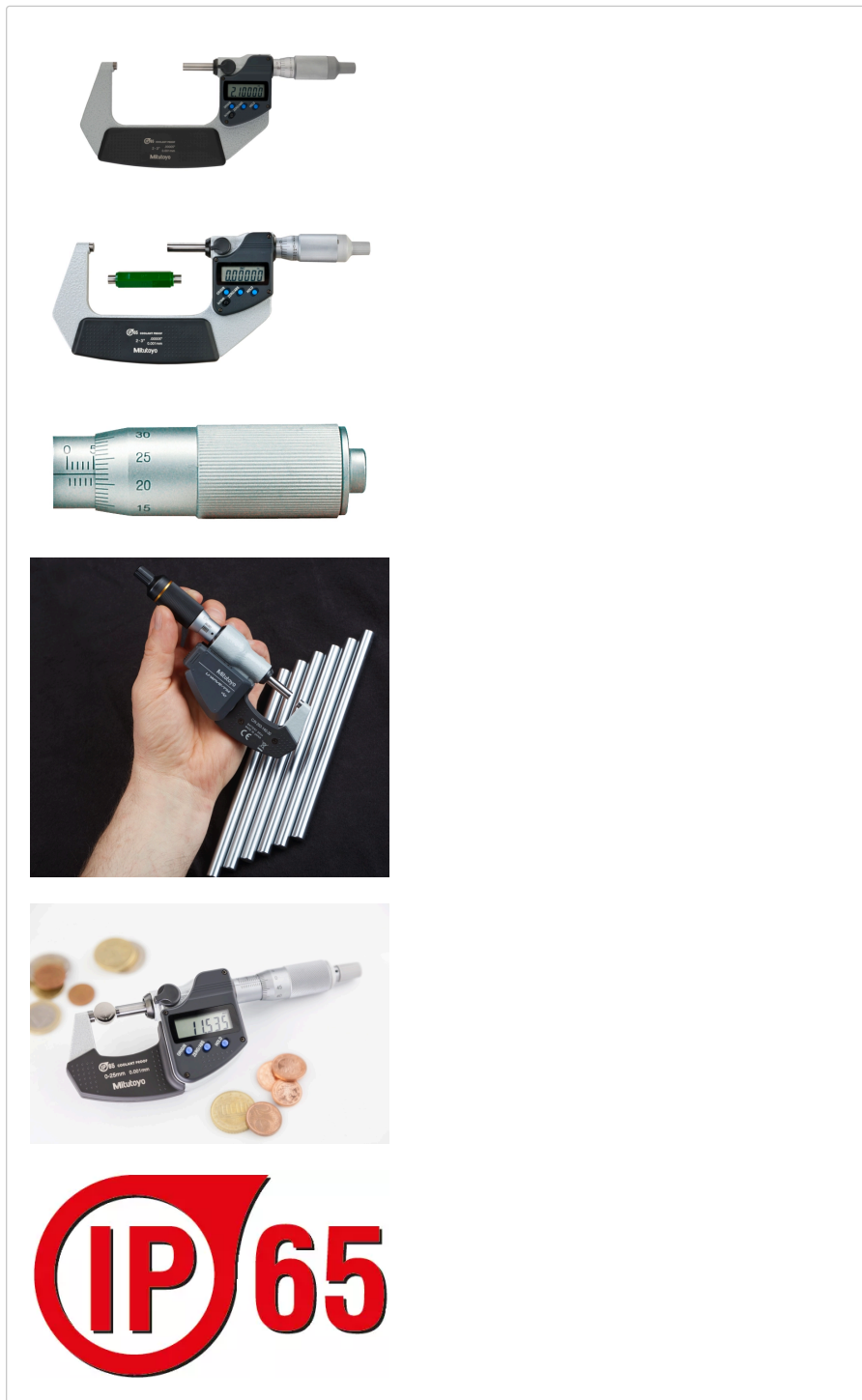

Description


A Mitutoyo waterproof digital micrometer suitable for use in the presence of coolant or cutting oil. The highly stable frame incorporates a heat shield to preserve accuracy over extended measuring sessions. A ratchet thimble guarantees repeatable measurement.

Features

Model:	MDC-3"PXT
Digital/Analog:	Digital
Inch-Metric:	Inch/Metric
Range:	2 - 3 "

Digital step:	0.00005"/0.001 mm
Max. Permissible Error J MPE:	±0.0001"
Delivered:	Including box, spanner, SR44 battery, setting standard
Flatness:	0.000012"
Parallelism:	0.00008"
Display:	LCD, character height 7.5 mm
Measuring face:	Carbide-tipped, micro-lap finish
Measuring spindle:	With spindle lock, ø6,35 mm, spindle pitch 0,5 mm
Scale:	Thimble and sleeve satin chrome finish, ø18 mm
Data output:	No
Measuring force:	7 - 12 N
Power supply:	1 battery SR-44
Battery life:	Approx. 2.4 years for models ≤4" 1.2 years for >4"
ABS / INC (INC ZERO):	Yes
Auto Power OFF after 20 min. non use:	Yes
Low voltage alarm:	Yes
Function lock:	Yes
HOLD:	Yes
2 x PRESET (over 100 mm):	Yes
Mass:	480 g

Dimensions

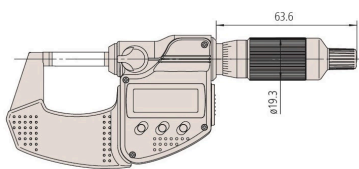

L: 50 mm

a: 10.1 mm

b: 47 mm

c: 2.5 mm

Accessories

Optional accessories:

Promotion!



Micrometer Stand, Adjustable Angle Type

for Micrometer 0-100mm/0-4"

Art No. 156-101-10

Promo price: **56.00 €***

Suggested retail price: ~~70.00 €*~~

Standard accessories:



Micrometer Setting Standard

Length: 2"

Art No. 167-142

Suggested retail price: 36.00 €*

Spare parts

Consumable spares:



Battery SR44 1,5 V

Art No. 938882

Suggested retail price: 7.00 €*