


Digital Micrometer IP65,  
Inch/Metric

Item number: 293-348-30

Images

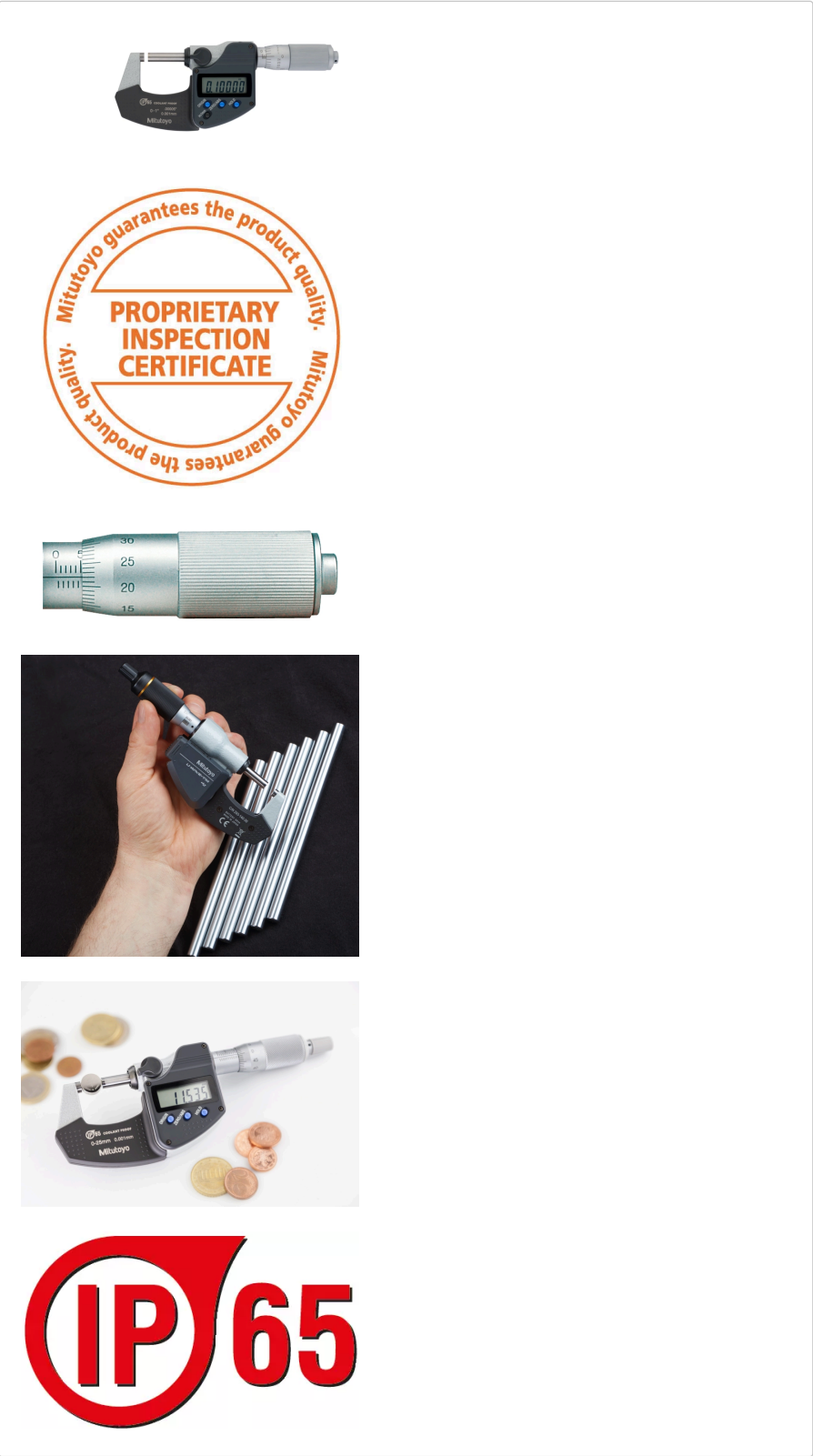

Description

A Mitutoyo waterproof digital micrometer suitable for use in the presence of coolant or cutting oil. The highly stable frame incorporates a heat shield to preserve accuracy over extended measuring sessions. A ratchet stop guarantees repeatable measurement.

Features

|                 |         |
|-----------------|---------|
| Digital/Analog: | Digital |
|-----------------|---------|

|                                              |                                                                 |
|----------------------------------------------|-----------------------------------------------------------------|
| <b>Inch-Metric:</b>                          | Inch/Metric                                                     |
| <b>Range:</b>                                | 0 - 1 "                                                         |
| <b>Digital step:</b>                         | 0.00005"/0.001 mm                                               |
| <b>Max. Permissible Error J MPE:</b>         | ±0.00005"                                                       |
| <b>Delivered:</b>                            | Including box, spanner, SR44 battery, certificate of inspection |
| <b>Flatness:</b>                             | 0.000012"                                                       |
| <b>Parallelism:</b>                          | 0.00004"                                                        |
| <b>Display:</b>                              | LCD, character height 7.5 mm                                    |
| <b>Measuring face:</b>                       | Carbide-tipped, micro-lap finish                                |
| <b>Measuring spindle:</b>                    | With spindle lock, ø6,35 mm, spindle pitch 0,5 mm               |
| <b>Scale:</b>                                | Thimble and sleeve satin chrome finish, ø18 mm                  |
| <b>Data output:</b>                          | No                                                              |
| <b>Measuring force:</b>                      | 5 - 10 N                                                        |
| <b>Power supply:</b>                         | 1 battery SR-44                                                 |
| <b>Battery life:</b>                         | Approx. 2.4 years for models ≤4"<br>1.2 years for >4"           |
| <b>ABS / INC (INC ZERO):</b>                 | Yes                                                             |
| <b>Auto Power OFF after 20 min. non use:</b> | Yes                                                             |
| <b>Low voltage alarm:</b>                    | Yes                                                             |
| <b>Function lock:</b>                        | Yes                                                             |
| <b>HOLD:</b>                                 | Yes                                                             |
| <b>2 x PRESET (over 100 mm):</b>             | Yes                                                             |
| <b>Mass:</b>                                 | 275 g                                                           |

## Dimensions

**L:** 0 mm

**a:** 6.5 mm

**b:** 25 mm

**c:** 2.5 mm

## Accessories

Optional accessories:



## Micrometer Stand, 45° Angle Type

for Micrometer 0-50mm/0-2"

Art No. 156-105-10

Suggested retail price: 58.00 €\*  
[View product](#)

Promotion!



## Micrometer Stand, Adjustable Angle Type

for Micrometer 0-100mm/0-4"

Art No. 156-101-10

Promo price: **56.00 €\*  
~~70.00 €\*~~**

Suggested retail price: 70.00 €\*  
[View product](#)

### Spare parts

Consumable spares:



## Battery SR44 1,5 V

Art No. 938882

Suggested retail price: 7.00 €\*  
[View product](#)