

Digital Micrometer IP65, Inch/Metric

Item number: 293-354-30

Images



Description

This IP65 Micrometer offers outstanding accuracy, with and without data output, is highly robust and offers the following benefits:

- Oil-resistant material used for all plastic parts
- Extraordinary battery life of 2,4 years*
- Excellent resistance against water and dust enables this micrometer to be used in machining situations that include splashing coolant fluid.


Features

Digital/Analog:

Digital

Inch-Metric:	Inch/Metric
Range:	8 - 9 "
Digital step:	0.0001"/0.001 mm
Max. Permissible Error J MPE:	±0.00015"
Delivered:	Including box, spanner, SR44 battery, setting standard
Flatness:	0.000012"
Parallelism:	0.00016"
Display:	LCD, character height 7.5 mm
Measuring face:	Carbide-tipped, micro-lap finish
Measuring spindle:	With spindle lock, ø6,35 mm, spindle pitch 0,5 mm
Scale:	Thimble and sleeve satin chrome finish, ø18 mm
Data output:	Yes
Measuring force:	5 - 10 N
Power supply:	1 battery SR-44
Battery life:	Approx. 2.4 years for models ≤4" 1.2 years for >4"
ABS / INC (INC ZERO):	Yes
Auto Power OFF after 20 min. non use:	Yes
Low voltage alarm:	Yes
Function lock:	Yes
HOLD:	Yes
2 x PRESET (over 100 mm):	Yes
Mass:	1100 g

Dimensions

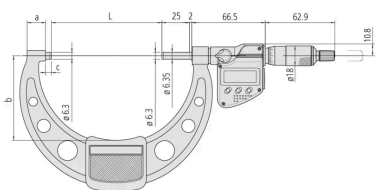

L: 200 mm

a: 16.8 mm

b: 126 mm

c: 6.7 mm

Accessories

Optional accessories:



Micrometer Stand

for Micrometer 100-300mm/5-12"

Art No. 156-102

Suggested retail price: 699.00 €*
Suggested retail price: 699.00 €*
Suggested retail price: 699.00 €*

Promotion!



Connection Unit for IP Caliper, Micrometer

with Data Button for U-WAVE fit, U-WAVE fit Bluetooth

Art No. 02AZF310

Promo price: 76.00 €*
Suggested retail price: 110.00 €*

Suggested retail price: 110.00 €*

Promotion!



USB Input Tool Direct (Digimatic to USB)

2m Cable, Digimatic/Digimatic 2, with Data Button IP Micrometer Type

Art No. 06AFM380B

Promo price: 111.00 €*
Suggested retail price: 141.00 €*

Suggested retail price: 141.00 €*



Digimatic Cable with Data Button IP Type

1 m, Micrometer Type

Art No. 05CZA662

Suggested retail price: 105.00 €*
Suggested retail price: 105.00 €*

Suggested retail price: 105.00 €*



Digimatic Cable with Data Button IP Type

2 m, Micrometer Type

Art No. 05CZA663

Suggested retail price: 107.00 €*
Suggested retail price: 107.00 €*

Suggested retail price: 107.00 €*

Promotion!



U-WAVE fit, IP67 Type

Wireless Transmitter for
Micrometer/Indicator
Art No. 264-622

Promo price: **129.00 €***
Suggested retail price: ~~185.00 €*~~

Promotion!



U-WAVE fit, Buzzer Type

Wireless Transmitter for
Micrometer/Indicator
Art No. 264-623

Promo price: **129.00 €***
Suggested retail price: ~~185.00 €*~~

Promotion!



U-WAVE fit Bluetooth, IP67 Type

Wireless Transmitter for
Micrometer/Indicator
Art No. 264-626

Promo price: **129.00 €***
Suggested retail price: ~~185.00 €*~~

Promotion!



U-WAVE fit Bluetooth, Buzzer Type

Wireless Transmitter for
Micrometer/Indicator
Art No. 264-627

Promo price: **129.00 €***
Suggested retail price: ~~185.00 €*~~

Promotion!

Mitutoyo


MiCAT
the standard in world
metrology software
MesurLink

USB-ITPAK Vers. 3.0

USB Dongle + Manual (Software available
Online)

Art No. 06AGR543

Promo price: **268.00 €***
Suggested retail price: ~~340.00 €*~~

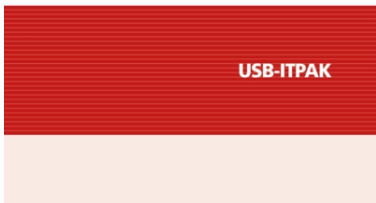

Standard accessories:

Micrometer Setting Standard

Length: 8"

Art No. 167-148

Suggested retail price: 50.00 €*



Spare parts

Consumable spares:



Battery SR44 1,5 V

Art No. 938882

Suggested retail price: 7.00 €*
