
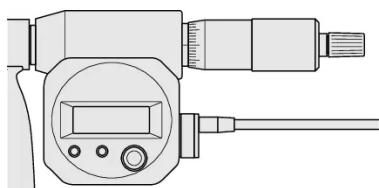


## Digital Micrometer

Item number: 293-584

### Images

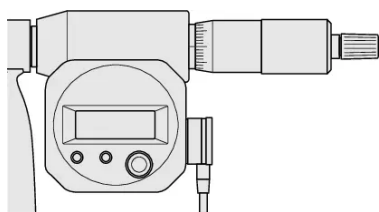

### Description

This Wide Measuring Range Digimatic Micrometer with data output offers the following benefits:

- The micrometer's 330° rotatable display unit enables easy reading in all measurement positions.
- With Carbide-tipped measuring faces

### Features

<b>Model:</b>	MDC-375MB
<b>Digital/Analog:</b>	Digital
<b>Inch-Metric:</b>	Metric
<b>Range:</b>	350 - 375 mm
<b>Digital step:</b>	0.001 mm
<b>Max. Permissible Error J MPE:</b>	±6 μm
<b>Delivered:</b>	Including box, spanner, SR44 battery, setting standard
<b>Flatness:</b>	0.6 μm
<b>Parallelism:</b>	5 μm
<b>Display:</b>	LCD, character height 7.5 mm
<b>Measuring face:</b>	Carbide-tipped, micro-lap finish

<b>Measuring spindle:</b>	With spindle lock, ø8 mm, spindle pitch 0.5 mm
<b>Scale:</b>	Thimble and sleeve satin chrome finish, ø21 mm
<b>Data output:</b>	Yes
<b>Measuring force:</b>	10 - 14 N
<b>Power supply:</b>	2 batteries SR-44
<b>Battery life:</b>	Approx. 1.8 years
<b>ABS / INC (INC ZERO):</b>	Yes
<b>Auto Power OFF after 20 min. non use:</b>	Yes
<b>Low voltage alarm:</b>	Yes
<b>Function lock:</b>	Yes
<b>HOLD:</b>	Yes
<b>2 x PRESET:</b>	Yes
<b>Mass:</b>	2300 g

## Accessories

### Optional accessories:



### Micrometer Stand

for Micrometer 300-1000mm/12-40"

Art No. 156-103

Suggested retail price: 1,302.00 €\*

Promotion!



### Connection Cable C for U-WAVE

Straight, with Data Button

Art No. 02AZD790C

Promo price: **72.00 €\***

Suggested retail price: 105.00 €\*

Promotion!



### USB Input Tool Direct (Digimatic to USB)

2m Cable, Digimatic/Digimatic 2, Straight,  
with Data Button

Art No. 06AFM380C

Promo price: **98.00 €\***

Suggested retail price: ~~124.00 €\*~~



### Digimatic Cable, Straight, Data Button,

1 m

Art No. 959149

Suggested retail price: 48.00 €\*



### Digimatic Cable, Straight, Data Button

2 m

Art No. 959150

Suggested retail price: 57.00 €\*



### Digimatic Cable with Data Button

1 m, Flat L-Shape Left Type

Art No. 04AZB512

Suggested retail price: 95.00 €\*



### Digimatic Cable, Straight, Data Button

2 m, Flat L-Shape Left Type

Art No. 04AZB513

Suggested retail price: 106.00 €\*

Promotion!



### U-WAVE-T, IP67 Type

Wireless Transmitter

Art No. 02AZD730G

Promo price: **129.00 €\***

Suggested retail price: ~~187.00 €\*~~

Promotion!



### U-WAVE-T, Buzzer Type

Wireless Transmitter

Art No. 02AZD880G

Promo price: **129.00 €\***

Suggested retail price: ~~187.00 €\*~~

Standard accessories:

### Micrometer Setting Standard

Length: 350mm

Art No. 167-114

Suggested retail price: **93.00 €\***



Spare parts

Consumable spares:



### Battery SR44 1,5 V

Art No. 938882

Suggested retail price: **7.00 €\***

