
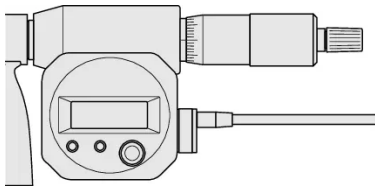


Digital Micrometer

Item number: 293-585

Images

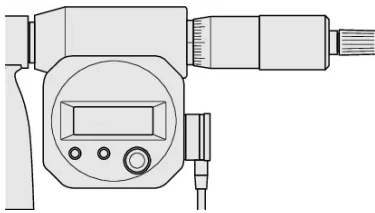

Description

This Wide Measuring Range Digimatic Micrometer with data output offers the following benefits:

- The micrometer's 330° rotatable display unit enables easy reading in all measurement positions.
- With Carbide-tipped measuring faces

Features

Model:	MDC-400MB
Digital/Analog:	Digital
Inch-Metric:	Metric
Range:	375 - 400 mm
Digital step:	0.001 mm
Max. Permissible Error J MPE:	±7 μm
Delivered:	Including box, spanner, SR44 battery, setting standard
Flatness:	0.6 μm
Parallelism:	6 μm
Display:	LCD, character height 7.5 mm
Measuring face:	Carbide-tipped, micro-lap finish

Measuring spindle:	With spindle lock, ø8 mm, spindle pitch 0.5 mm
Scale:	Thimble and sleeve satin chrome finish, ø21 mm
Data output:	Yes
Measuring force:	10 - 14 N
Power supply:	2 batteries SR-44
Battery life:	Approx. 1.8 years
ABS / INC (INC ZERO):	Yes
Auto Power OFF after 20 min. non use:	Yes
Low voltage alarm:	Yes
Function lock:	Yes
HOLD:	Yes
2 x PRESET:	Yes
Mass:	2450 g

Accessories

Optional accessories:



Micrometer Stand

for Micrometer 300-1000mm/12-40"
 Art No. 156-103
 Suggested retail price: 1,302.00 €*

Promotion!



Connection Cable C for U-WAVE

Straight, with Data Button
 Art No. 02AZD790C
Promo price: 72.00 €*
 Suggested retail price: 105.00 €*

Promotion!



USB Input Tool Direct (Digimatic to USB)

2m Cable, Digimatic/Digimatic 2, Straight,
with Data Button
Art No. 06AFM380C

Promo price: **98.00 €***

Suggested retail price: ~~124.00 €*~~



Digimatic Cable, Straight, Data Button,

1 m

Art No. 959149

Suggested retail price: 48.00 €*



Digimatic Cable, Straight, Data Button

2 m

Art No. 959150

Suggested retail price: 57.00 €*



Digimatic Cable with Data Button

1 m, Flat L-Shape Left Type

Art No. 04AZB512

Suggested retail price: 95.00 €*



Digimatic Cable, Straight, Data Button

2 m, Flat L-Shape Left Type

Art No. 04AZB513

Suggested retail price: 106.00 €*

Promotion!



U-WAVE-T, IP67 Type

Wireless Transmitter

Art No. 02AZD730G

Promo price: **129.00 €***

Suggested retail price: ~~187.00 €*~~

Promotion!



U-WAVE-T, Buzzer Type

Wireless Transmitter

Art No. 02AZD880G

Promo price: **129.00 €***

Suggested retail price: ~~187.00 €*~~

Promotion!

Mitutoyo

MiCAT

the standard in world
metrology software
measurLink®

USB-ITPAK Vers. 3.0

USB Dongle + Manual (Software available
Online)

Art No. 06AGR543

Promo price: **268.00 €***

Suggested retail price: ~~340.00 €*~~



Standard accessories:

Micrometer Setting Standard

Length: 375mm

Art No. 167-115

Suggested retail price: **101.00 €***



Spare parts

Consumable spares:



Battery SR44 1,5 V

Art No. 938882

Suggested retail price: 7.00 €*
