

Digital Absolute Micrometer

QuickMike

Item number: 293-666-20

Images



Dust- and
Water-
Protected

www.tuv.com
ID 0000063013

ABSOLUTE®

IP65

Description

This Quickmike, with a non-rotating spindle, delivers much faster movement than standard models.

The ABSOLUTE Digimatic Micrometer Quickmike offers the following benefits:


- With 10 mm feed per thimble rotation, it delivers twenty times as fast as standard devices.
- Excellent resistance against water and dust (IP65) enables this micrometer to be used in machining situations that include splashing coolant fluid.
- ABSOLUTE linear scale means no restriction on adjustment speed.
- Larger measuring range - 30 mm compared with 25 mm - than standard micrometer.

Features

Model:	MDQ-30MX
Digital/Analog:	Digital
Inch-Metric:	Metric
Range:	0 - 30 mm
Digital step:	0.001 mm
Max. Permissible Error J MPE:	±2 µm
Delivered:	Including box, SR44 battery
Flatness:	0.3 µm
Parallelism:	2 µm
Display:	LCD, character height 10 mm
Measuring face:	Carbide-tipped, micro-lap finish

Measuring spindle:	ø6.35 mm, non-rotating, spindle feed 10 mm
Data output:	Yes
Measuring force:	5 - 12 N
Power supply:	1 battery SR-44
Battery life:	Approx. 5 years
ON/OFF:	Yes
ORIGIN:	Yes
ABS / INC (INC ZERO):	Yes
Low voltage alarm:	Yes
Function lock:	Yes
HOLD:	Yes
Mass:	275 g

Dimensions

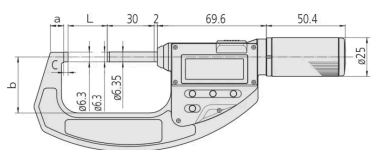

L: 0 mm

a: 7 mm

b: 25 mm

c: 2 mm

Accessories

Optional accessories:

Promotion!



Micrometer Stand, Adjustable Angle Type
for Micrometer 0-100mm/0-4"
Art No. 156-101-10
Promo price: **56.00 €***
Suggested retail price: ~~70.00 €*~~

Promotion!



Connection Cable B for U-WAVE
with Data Button for IP Micrometer Type
Art No. 02AZD790B
Promo price: **76.00 €***
Suggested retail price: ~~110.00 €*~~

Promotion!



USB Input Tool Direct (Digimatic to USB)

2m Cable, Digimatic/Digimatic 2, with Data
Button IP Micrometer Type
Art No. 06AFM380B

Promo price: **111.00 €***

Suggested retail price: ~~141.00 €*~~



Digimatic Cable with Data Button IP Type

1 m, Micrometer Type
Art No. 05CZA662

Suggested retail price: 105.00 €*



Digimatic Cable with Data Button IP Type

2 m, Micrometer Type
Art No. 05CZA663

Suggested retail price: 107.00 €*

Promotion!



U-WAVE-T, IP67 Type

Wireless Transmitter
Art No. 02AZD730G

Promo price: **129.00 €***

Suggested retail price: ~~187.00 €*~~

Promotion!



U-WAVE-T, Buzzer Type

Wireless Transmitter
Art No. 02AZD880G

Promo price: **129.00 €***

Suggested retail price: ~~187.00 €*~~

Promotion!

Mitutoyo

MiCAT

the standard in world
metrology software
MeasurLink®

USB-ITPAK Vers. 3.0

USB Dongle + Manual (Software available
Online)

Art No. 06AGR543

Promo price: 268.00 €*

~~Suggested retail price: 340.00 €*~~

USB-ITPAK

Spare parts

Consumable spares:



Battery SR44 1,5 V

Art No. 938882

Suggested retail price: 7.00 €*