

Digital Micrometer

Item number: 293-821-30

Images



Description


A Mitutoyo basic, cost-effective digital micrometer. The highly stable frame incorporates a heat shield to preserve accuracy over extended measuring sessions. A ratchet stop guarantees repeatable measurement.

Features

Model:	MDC-25SX
Digital/Analog:	Digital
Inch-Metric:	Metric
Range:	0 - 25 mm
Digital step:	0.001 mm
Max. Permissible Error J MPE:	$\pm 2 \mu\text{m}$
Delivered:	Including box, spanner, SR44 battery, certificate of inspection
Flatness:	0.3 μm
Parallelism:	1 μm
Display:	LCD, character height 7.5 mm
Measuring face:	Carbide-tipped, micro-lap finish
Measuring spindle:	$\varnothing 6,35$ mm, spindle pitch 0,5 mm
Scale:	Thimble and sleeve satin chrome finish, $\varnothing 18$ mm
Data output:	No
Measuring force:	5 - 10 N
Power supply:	1 battery SR-44

Battery life:	Approx. 2.4 years
ORIGIN:	Yes
Auto Power OFF after 20 min. non use:	Yes
Low voltage alarm:	Yes
Function lock:	Yes
Mass:	275 g

Dimensions

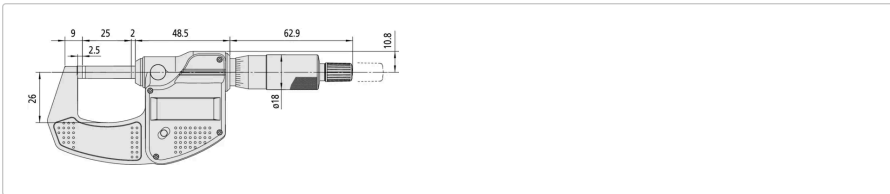

Accessories

Optional accessories:



Micrometer Stand, 45° Angle Type

for Micrometer 0-50mm/0-2"
 Art No. 156-105-10
 Suggested retail price: 58.00 €*



Micrometer Stand, Adjustable Angle Type

for Micrometer 0-100mm/0-4"
 Art No. 156-101-10
Promo price: 56.00 €*
 Suggested retail price: 70.00 €*

Spare parts

Consumable spares:



Battery SR44 1,5 V

Art No. 938882

Suggested retail price: 7.00 €*
