


Digital Micrometer, Inch/Metric

Item number: 293-831-30

Images

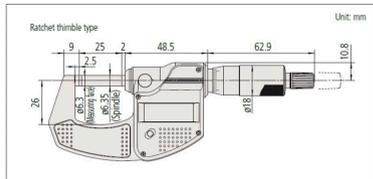

Description


A basic, cost-effective Mitutoyo digital micrometer. The highly stable frame incorporates a heat shield to preserve accuracy over extended measuring sessions. A ratchet stop guarantees repeatable measurement.

Features

Digital/Analog:	Digital
Inch-Metric:	Inch/Metric
Range:	0 - 1 "
Digital step:	0.00005"/0.001 mm
Max. Permissible Error J MPE:	±0.0001"
Delivered:	Including box, spanner, SR44 battery, certificate of inspection
Flatness:	0.000012"
Parallelism:	0.00008"
Display:	LCD, character height 7.5 mm
Measuring face:	Carbide-tipped, micro-lap finish
Measuring spindle:	ø 6.35 mm, spindle pitch 0.635 mm

Scale:	Thimble and sleeve satin chrome finish, ø18 mm
Data output:	No
Measuring force:	5 - 10 N
Power supply:	1 battery SR-44
Battery life:	Approx. 2.4 years
ORIGIN:	Yes
Auto Power OFF after 20 min. non use:	Yes
Low voltage alarm:	Yes
Function lock:	Yes
Mass:	275 g

Dimensions

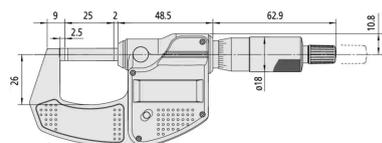

Accessories

Optional accessories:



Micrometer Stand, 45° Angle Type

for Micrometer 0-50mm/0-2"
 Art No. 156-105-10
 Suggested retail price: 58.00 €*



Micrometer Stand, Adjustable Angle Type

for Micrometer 0-100mm/0-4"
 Art No. 156-101-10
Promo price: 56.00 €*
 Suggested retail price: 70.00 €*

Spare parts

Consumable spares:



Battery SR44 1,5 V

Art No. 938882

Suggested retail price: 7.00 €*
