


# Digital Micrometer, Inch/Metric

Item number: 293-832-30

## Images

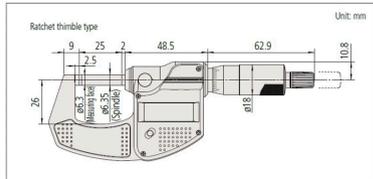

## Description


A Mitutoyo basic, cost-effective digital micrometer. The highly stable frame incorporates a heat shield to preserve accuracy over extended measuring sessions. A friction thimble guarantees repeatable measurement.

## Features

<b>Digital/Analog:</b>	Digital
<b>Inch-Metric:</b>	Inch/Metric
<b>Range:</b>	0 - 1 "
<b>Digital step:</b>	0.00005"/0.001 mm
<b>Max. Permissible Error J MPE:</b>	±0.0001"
<b>Delivered:</b>	Including box, spanner, SR44 battery, certificate of inspection
<b>Flatness:</b>	0.000012"
<b>Parallelism:</b>	0.00008"
<b>Display:</b>	LCD, character height 7.5 mm
<b>Measuring face:</b>	Carbide-tipped, micro-lap finish
<b>Measuring spindle:</b>	ø 6.35 mm, spindle pitch 0.635 mm

<b>Scale:</b>	Thimble and sleeve satin chrome finish, ø18 mm
<b>Data output:</b>	No
<b>Measuring force:</b>	5 - 10 N
<b>Power supply:</b>	1 battery SR-44
<b>Battery life:</b>	Approx. 2.4 years
<b>ORIGIN:</b>	Yes
<b>Auto Power OFF after 20 min. non use:</b>	Yes
<b>Low voltage alarm:</b>	Yes
<b>Function lock:</b>	Yes
<b>Mass:</b>	275 g

**Dimensions**

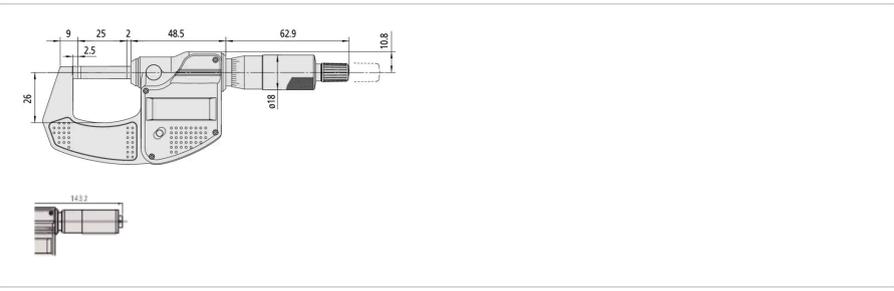

**Accessories**

Optional accessories:



**Micrometer Stand, 45° Angle Type**

for Micrometer 0-50mm/0-2"  
 Art No. 156-105-10  
 Suggested retail price: 58.00 €\*



**Micrometer Stand, Adjustable Angle Type**

for Micrometer 0-100mm/0-4"  
 Art No. 156-101-10  
**Promo price: 56.00 €\***  
 Suggested retail price: 70.00 €\*

**Spare parts**

Consumable spares:



## Battery SR44 1,5 V

Art No. 938882

Suggested retail price: 7.00 €\*  

---