


Dial Gauge, ISO Type

Item number: 2960A

Images

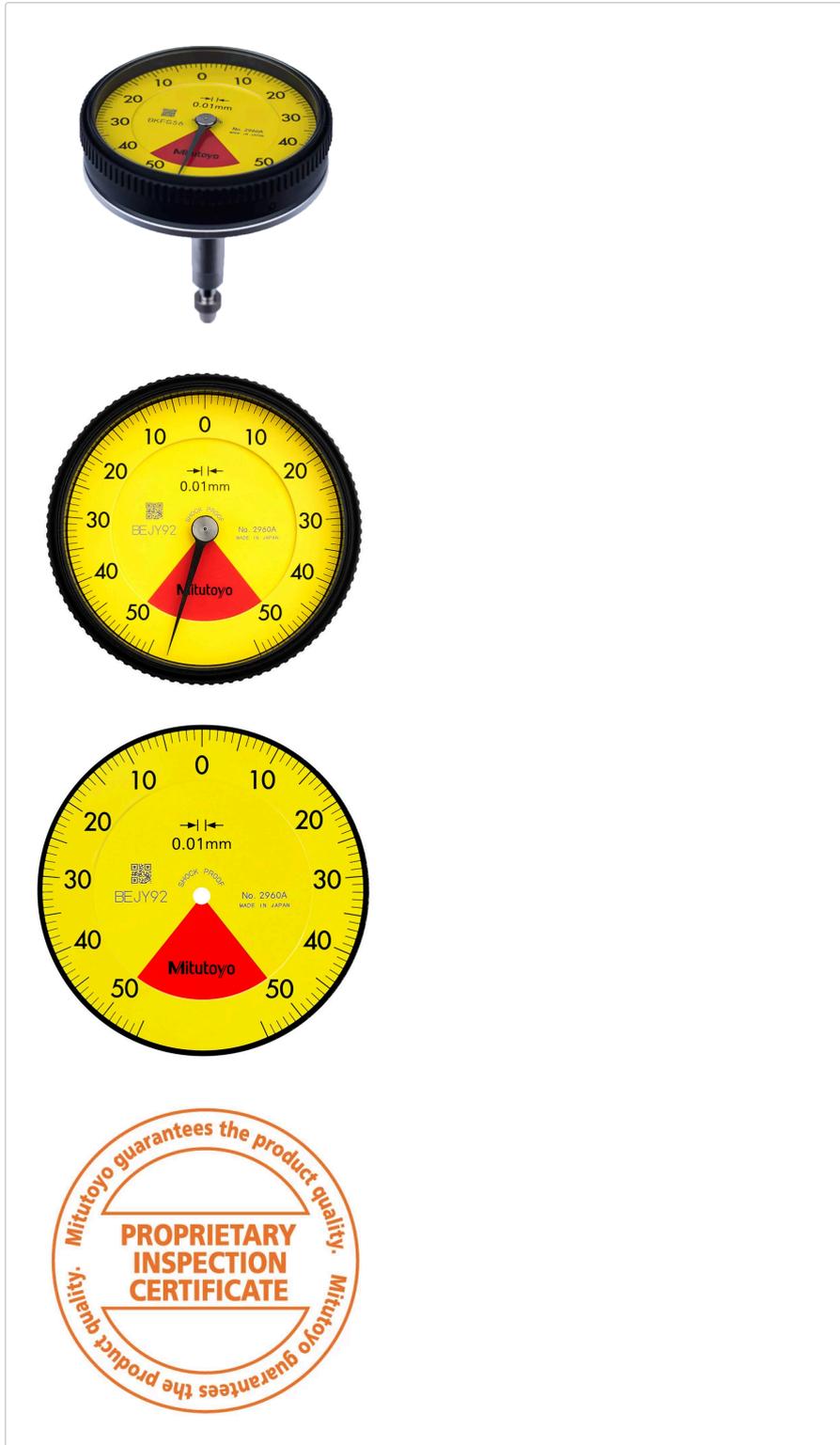

Description


This is a back plunger type dial indicator with bezel \varnothing 57 mm.

Features

Digital/Analog:	Analog
Inch-Metric:	Metric
Type:	EN ISO Standard
Range:	1 mm

Plunger Stroke:	4 mm
Range per rev.:	1,27 mm
Dial reading:	50-0-50
Delivered:	With certificate of inspection
Graduation:	0.01 mm
MPE any 1/10 revolution:	7 μ m
MPE measuring range:	15 μ m
H MPE (Hysteresis):	3.5 μ m
R MPE (Repeatability):	3 μ m
Measuring force:	0,4-1,4 N
Stem:	8 mm
Contact point:	Carbide tipped, thread: M 2.5 x 0.45 mm
Balanced dial:	Yes
One revolution:	Yes
Shockproof:	Yes
Mass:	115 g

Dimensions

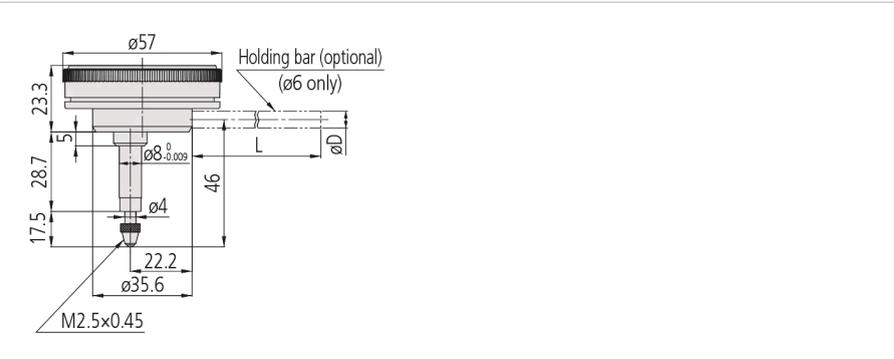

Accessories

Optional accessories:



Limit Hands (green) 2pcs

Dial Indicator Series 2/3/4
 Art No. 21AZB195
 Price on application



Holding Bar for Back Plunger Indicator

Ø 6 mm, 81 mm Length
Art No. 136567
Suggested retail price: 7.90 €*



Holding Bar for Back Plunger Indicator

Ø 6 mm, 42 mm Length
Art No. 21AAA166
Suggested retail price: 5.80 €*

Spare parts

Consumable spares:



Contact Element Ball Point, M2,5x0,45

8,3mm Length, Metric
Art No. 21AZA319
Suggested retail price: 6.30 €*
