

Dial Gauge, ISO Type

Item number: 2990A-10

Images



Description


This is a back plunger type dial indicator with bezel \varnothing 57 mm.

Features

Digital/Analog:	Analog
Inch-Metric:	Metric
Type:	EN ISO Standard
Range:	0.1 mm
Plunger Stroke:	4 mm
Range per rev.:	0,14 mm
Dial reading:	50-0-50
Delivered:	With certificate of inspection
Graduation:	0.001 mm
MPE any 1/10 revolution:	2 μ m
MPE measuring range:	4 μ m
H MPE (Hysteresis):	2 μ m
R MPE (Repeatability):	1 μ m
Measuring force:	0,4-1,5 N
Stem:	8 mm

Contact point:	Carbide tipped, thread: M 2.5 x 0.45 mm
Balanced dial:	Yes
One revolution:	Yes
Shockproof:	Yes
Mass:	205 g

Dimensions

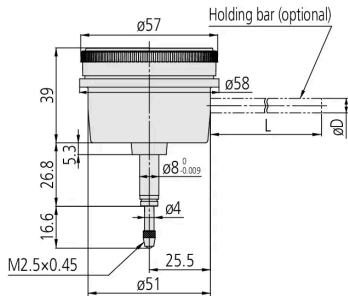

Accessories

Optional accessories:



Holding Bar for Back Plunger Indicator

Ø 8 mm, 81 mm Length
 Art No. 136568
 Suggested retail price: 5.30 €*



Limit Hands (green) 2pcs

Dial Indicator Series 2/3/4
 Art No. 21AZB195
 Price on application



Holding Bar for Back Plunger Indicator

Ø 6 mm, 42 mm Length
 Art No. 21AAA166
 Suggested retail price: 5.80 €*



Holding Bar for Back Plunger Indicator

Ø 6 mm, 81 mm Length
Art No. 136567
Suggested retail price: 7.90 €*



Holding Bar for Back Plunger Indicator

Ø6,35mm, 81mm Length
Art No. 124625
Suggested retail price: 7.90 €*



Holding Bar for Back Plunger Indicator

Ø6,35mm, 42mm Length
Art No. 21AAA167
Suggested retail price: 5.80 €*



Holding Bar for Back Plunger Indicator

Ø 8 mm, 42 mm Length
Art No. 21AAA168
Suggested retail price: 6.30 €*

Spare parts

Consumable spares:



**Contact Element Ball Point,
M2,5x0,45**

7,3mm Length, Carbide, Metric

Art No. 901312

Suggested retail price: 5.00 €*
