


PJ-P1010A

Item number: 302-801-10

Images

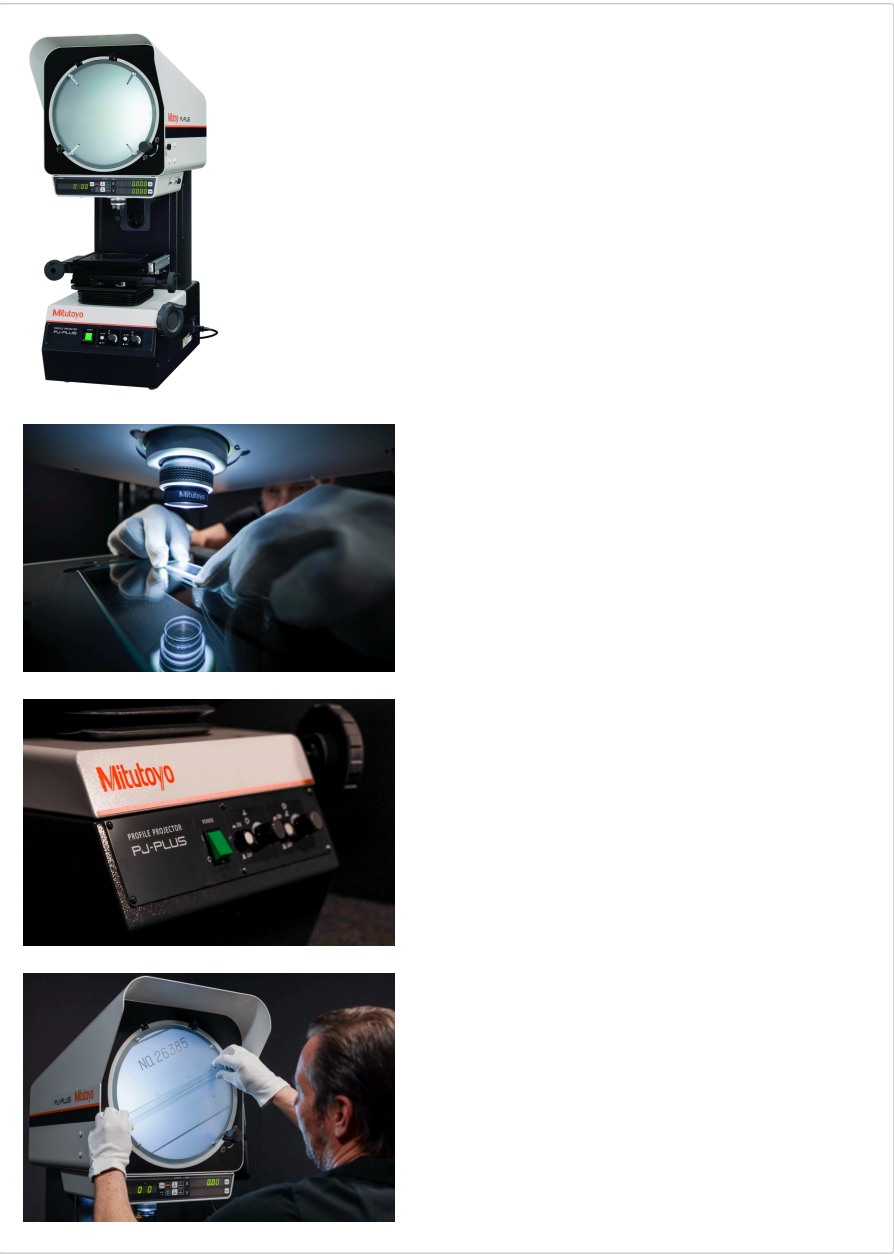

Description

The measuring projector that “can be operated intuitively” even by inexperienced people and also has excellent durability and energy-saving performance thanks to the adoption of an “LED illumination source” and “fanless cooling system”. It provides stable dimension and angle measurements in harsher environments, such as manufacturing and processing lines, than can be handled by conventional models.

Features

Model:	PJ-P1010A
Measuring range XY:	100 x 100 mm
Model:	PJ-P1010A
XY stage table top size:	250 x 250 mm
XY stage effective area:	142 x 142 mm
Stage glass No.:	12BAE041
Max stage loading:	10 kg

Mass:

114 kg

Accessories

Optional accessories:



Inspection tool
Standard scale 50 mm/0,1 mm
Art No. 172-116
Suggested retail price: 189.00 €*



Inspection tool
Reading scale 200 mm/0,5 mm
Art No. 172-118
Suggested retail price: 313.00 €*



Inspection tool
Reading scale 8"/0.02"
Art No. 172-119
Suggested retail price: 313.00 €*



Inspection tool
Reading Scale 300 mm/0,5 mm
Art No. 172-161
Suggested retail price: 378.00 €*

Inspection tool

Reading Scale 12"/0.02"

Art No. 172-162

Suggested retail price: 378.00 €*


Green Filter, Colour filter

Art No. 172-160-3

Suggested retail price: 165.00 €*


Swivel center support

Fixture/clamping material

Art No. 172-604

Suggested retail price: 1,446.00 €*


Lens accessory

Oblique reflecting mirror for 10X lens

Art No. 172-229

Suggested retail price: 113.00 €*


Lens accessory

Oblique reflecting mirror for 20X lens

Art No. 172-230

Suggested retail price: 89.00 €*




V-BLOCK

with clamp

Art No. 172-378

Suggested retail price: **348.00 €***



Fixture/clamping material

Holder with clamp

Art No. 176-107

Suggested retail price: **296.00 €***



Swivel center support

Fixture/clamping material

Art No. 176-105

Suggested retail price: **1,054.00 €***



Attachment

OPTOEYE-200 Attachment A, 250-350 mm

Art No. 12AAE671

Suggested retail price: **45.00 €***




Sensor

Optoeye-200 edge detection sensor

Art No. 332-151

Suggested retail price: **1,634.00 €***

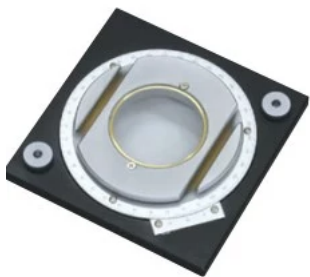

Rotary table

Art No. 176-106
Suggested retail price: 883.00 €*



Rotary table

100 mm for TM-1005B
Art No. 172-196
Suggested retail price: 1,086.00 €*



Rotary table

100 mm with fine feed knob for TM-1005B
Art No. 172-198
Suggested retail price: 1,083.00 €*



QM-DATA200 (Stand type)

2D Data processor w/o power cord
Art No. 264-160-13
Suggested retail price: 3,465.00 €*



QM-DATA200 (Arm type)

2D Data processor w/o power cord
Art No. 264-161-13
Suggested retail price: 3,465.00 €*



LED Circular Illuminator (PJ-PLUS)

for 10x and 20x + adapter 12AAX044, w/o power cord

Art No. 172-502

Suggested retail price: 2,623.00 €*



DAMPING RING A (FOR PJ 20X)

to connect LED illumination 172-502 on 20x lens

Art No. 12AAX044

Suggested retail price: 82.50 €*



Projection lens set, 10X magnification

Art No. 172-296

Suggested retail price: 905.00 €*



Projection lens set, 20X magnification

Art No. 172-297

Suggested retail price: 905.00 €*



Projection lens set, 50X magnification

Art No. 172-298


Suggested retail price: 1,185.00 €*



Projection lens set, 100X magnification

Art No. 172-299

Suggested retail price: 1,185.00 €*

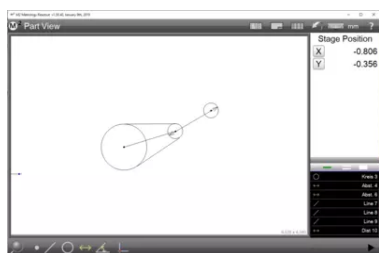


M2-2D software for PJ and PH series

Non-Edge detection unit incl. PC mounting kit

Art No. 63AAA406

Suggested retail price: 2,098.00 €*

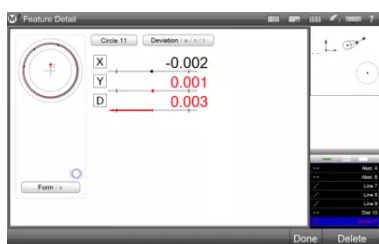

M2-2D software for PJ and PH series

Edge detection unit incl. PC mounting kit

Art No. 63AAA407

Suggested retail price: 3,595.00 €*



ASUS AiO PC for M2 system

Intel Celeron N4500/8GB/256GB

SSD/W11Pro/15.6" FHD Touch screen

Art No. 63AAA684

Price on application