


Dial Gauge, Lug Back, ISO Type

Item number: 3047A

Images

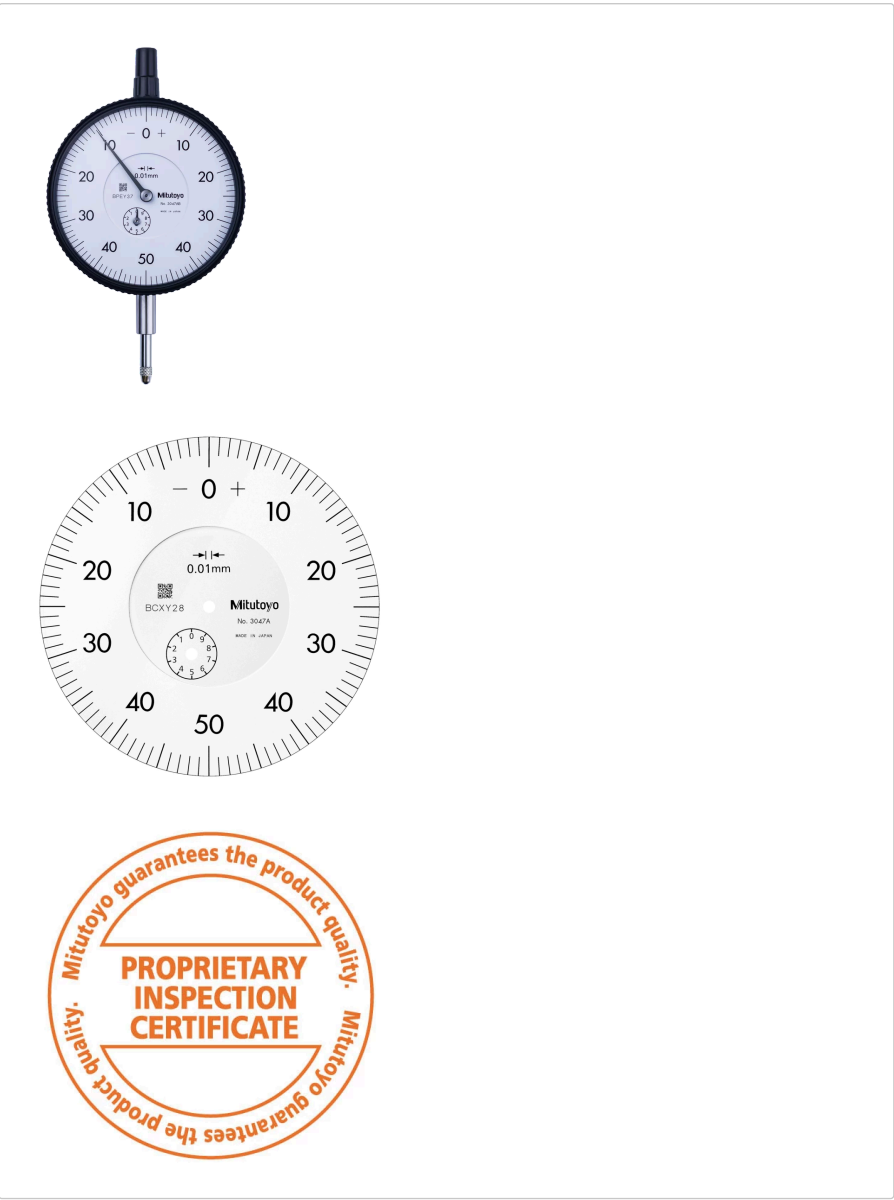

Description

- This is a standard dial indicator. It offers you the following benefits:
- Large-diameter dial face $\varnothing = 78\text{ mm}$ for easy reading
 - 0.01 / 0.001 mm graduation

Features

Digital/Analog:	Analog
Inch-Metric:	Metric
Type:	EN ISO Standard
Range:	10 mm
Range per rev.:	1 mm
Dial reading:	0-50-0
Delivered:	With certificate of inspection
Graduation:	0.01 mm

MPE any 1/10 revolution:	5 µm
MPE any 1/2 revolution:	9 µm
MPE any 1 revolution:	10 µm
MPE measuring range:	15 µm
H MPE (Hysteresis):	3 µm
R MPE (Repeatability):	3 µm
Measuring force:	0,4-1,4 N
Stem:	8 mm
Contact point:	Carbide tipped, thread: M 2.5 x 0.45 mm
Balanced dial:	Yes
Mass:	252 g

Dimensions

A: 59.6 mm

B: 75.5 mm

C: 78 mm

D: 17.7 mm

E: 21 mm

F: 15.9 mm

G: 20.6 mm

H: 71 mm

I: 9 mm

Accessories

Optional accessories:



Limit Hands (green) 2pcs

Dial Indicator Series 2/3/4
 Art No. 21AZB195
 Price on application



Bezel Clamp for Dial Gauge

Metric, Series 2/3/4

Art No. 21AZB148

Price on application



Spindle Lifting Lever

for Digital Indicator, A-Type Dial Indicator
Serie 2/3/4

Art No. 21EZA198

Price on application



Spindle Lifting Cable

for Indicator, L=500mm

Art No. 21JZA295

Price on application



Spindle Lifting Cable with Auto Stop

for Indicator, L=300mm

Art No. 21JZA301

Price on application

Spare parts

Consumable spares:



Contact Element Ball Point, M2,5x0,45

7,3mm Length, Carbide, Metric

Art No. 901312

Suggested retail price: **5.00 €***