

Dial Gauge, Flat Back, ISO Type

Item number: 3058AB-19

Images



Description

This is a standard dial indicator. It offers you the following benefits:


- Large-diameter dial face $\varnothing = 78$ mm for easy reading
- 0.01 / 0.001 mm graduation

Features

Digital/Analog:	Analog
Inch-Metric:	Metric
Type:	EN ISO Standard
Delivered:	With certificate of inspection
Range:	50 mm
Range per rev.:	1 mm
Dial reading:	$\pm 0-100$
Graduation:	0.01 mm
MPE any 1/10 revolution:	10 μm
MPE any 1/2 revolution:	12 μm
MPE any 1 revolution:	13 μm
MPE measuring range:	30 μm
H MPE (Hysteresis):	6 μm

R MPE (Repeatability):	3 µm
Measuring force:	0,4-3 N
Mass:	283 g
Stem:	8 mm
Contact point:	Carbide tipped, thread: M 2.5 x 0.45 mm
Coaxial revolution counter:	Yes
Shockproof:	Yes

Dimensions

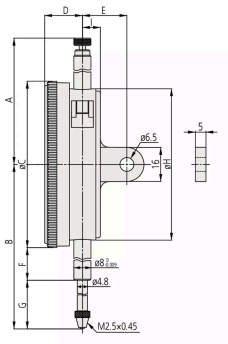

A:	81.9 mm
B:	142.3 mm
C:	78 mm
D:	17.7 mm
E:	21 mm
F:	43.9 mm
G:	59.4 mm
H:	71 mm
I:	9 mm

Accessories

Optional accessories:



Limit Hands (green) 2pcs

Dial Indicator Series 2/3/4
Art No. 21AZB195
[Price on application](#)



Bezel Clamp for Dial Gauge

Metric, Series 2/3/4
Art No. 21AZB148
[Price on application](#)

Spare parts

Consumable spares:



**Contact Element Ball Point,
M2,5x0,45**

8,3mm Length, Metric

Art No. 21AZA319

Suggested retail price: 17.00 €*
