


## Dial Gauge, Flat Back, ISO Type

Item number: 3060AB-19

### Images

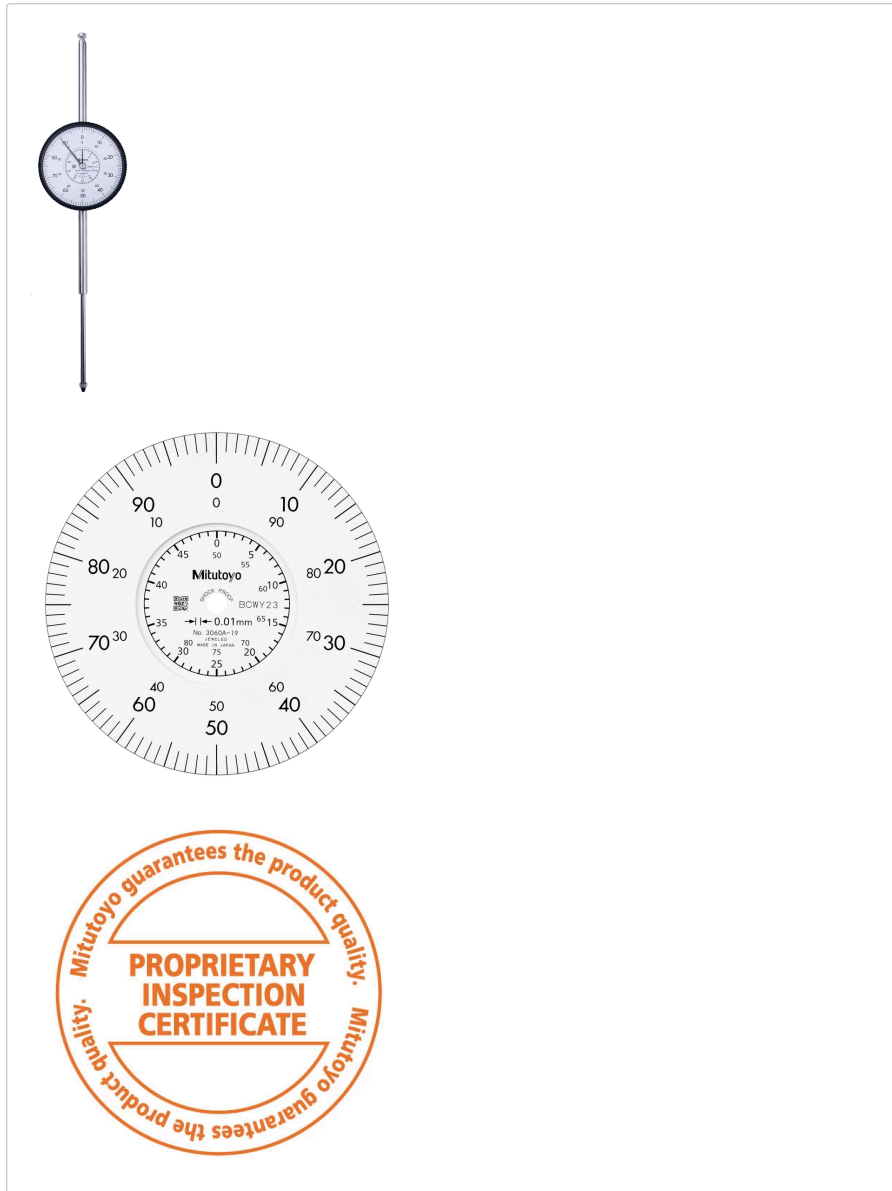

### Description

This is a standard dial indicator. It offers you the following benefits:


- Large-diameter dial face  $\varnothing = 78$  mm for easy reading
- 0.01 / 0.001 mm graduation

### Features

<b>Digital/Analog:</b>	Analog
<b>Inch-Metric:</b>	Metric
<b>Type:</b>	EN ISO Standard
<b>Delivered:</b>	With certificate of inspection
<b>Range:</b>	80 mm
<b>Range per rev.:</b>	1 mm
<b>Dial reading:</b>	$\pm 0-100$
<b>Graduation:</b>	0.01 mm

<b>MPE any 1/10 revolution:</b>	10 µm
<b>MPE any 1/2 revolution:</b>	14 µm
<b>MPE any 1 revolution:</b>	15 µm
<b>MPE measuring range:</b>	45 µm
<b>H MPE (Hysteresis):</b>	9 µm
<b>R MPE (Repeatability):</b>	3 µm
<b>Measuring force:</b>	0,4-3 N
<b>Mass:</b>	299 g
<b>Stem:</b>	8 mm
<b>Contact point:</b>	Carbide tipped, thread: M 2.5 x 0.45 mm
<b>Continuous dial:</b>	Yes
<b>Coaxial revolution counter:</b>	Yes
<b>Shockproof:</b>	Yes

## Dimensions

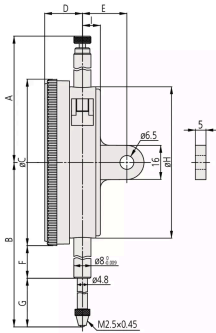

**A:** 120.9 mm

**B:** 202.3 mm

**C:** 78 mm

**D:** 17.7 mm

**E:** 21 mm

**F:** 73.9 mm

**G:** 89.4 mm

**H:** 71 mm

**I:** 9 mm

## Accessories

Optional accessories:



### Limit Hands (green) 2pcs

Dial Indicator Series 2/3/4

Art No. 21AZB195

Price on application



## Bezel Clamp for Dial Gauge

Metric, Series 2/3/4

Art No. 21AZB148

Price on application

### Spare parts

#### Consumable spares:



## Contact Element Ball Point, M2,5x0,45

8,3mm Length, Metric

Art No. 21AZA319

Suggested retail price: 17.00 €\*