


Dial Gauge, Flat Back, ISO Type

Item number: 3062AB-19

Images

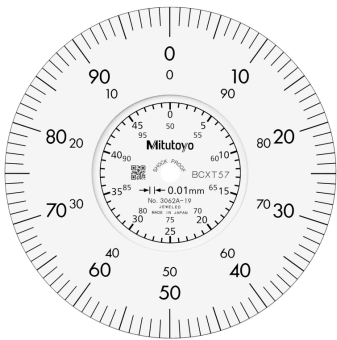

Description

This is a standard dial indicator. It offers you the following benefits:


- Large-diameter dial face $\varnothing = 78$ mm for easy reading
- 0.01 / 0.001 mm graduation

Features

Digital/Analog:	Analog
Inch-Metric:	Metric
Type:	EN ISO Standard
Range:	100 mm
Range per rev.:	1 mm
Dial reading:	$\pm 0-100$
Delivered:	With certificate of inspection
Graduation:	0.01 mm

MPE any 1/10 revolution:	12 μm
MPE any 1/2 revolution:	17 μm
MPE any 1 revolution:	20 μm
MPE measuring range:	50 μm
H MPE (Hysteresis):	9 μm
R MPE (Repeatability):	3 μm
Measuring force:	0,4-3,5 N
Stem:	8 mm
Contact point:	Carbide tipped, thread: M 2.5 x 0.45 mm
Continuous dial:	Yes
Coaxial revolution counter:	Yes
Shockproof:	Yes
Mass:	317 g

Dimensions

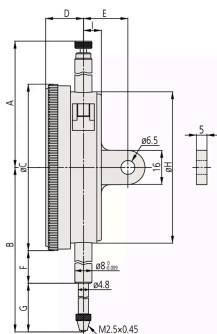

A: 141.9 mm

B: 243.3 mm

C: 78 mm

D: 17.7 mm

E: 21 mm

F: 94.9 mm

G: 109.4 mm

H: 71 mm

I: 9 mm

Accessories

Optional accessories:



Limit Hands (green) 2pcs

Dial Indicator Series 2/3/4

Art No. 21AZB195

Price on application



Bezel Clamp for Dial Gauge

Metric, Series 2/3/4

Art No. 21AZB148

Price on application

Spare parts

Consumable spares:



Contact Element Ball Point, M2,5x0,45

8,3mm Length, Metric

Art No. 21AZA319

Suggested retail price: 6.30 €*