

Digital 3 Flute V-Anvil Micrometer

Item number: 314-251-30

Images



Description

This Digimatic V-Anvil Micrometer helps you to measure cutting tools and taps. It offers the following benefits:

- It measures the outside diameter of cutting tools (such as taps, reamers, end mills) which have three flutes.
- V-anvils with a centreline groove are available for measuring the pitch diameter of taps by the single-wire method.

Features

Digital/Analog:	Digital
Delivered:	Including box, spanner, setting standard, 1 SR44 battery
Inch-Metric:	Metric
Range:	1 - 15 mm
Digital step:	0,001 mm
Max. Permissible Error J MPE:	±4 µm
Anvil:	With groove
Display:	LCD, character height 7.5 mm
Measuring face:	Prism angle 60°
Measuring spindle:	With spindle lock, ø6,35 mm, spindle pitch 0,75 mm
Scale:	Thimble and sleeve satin chrome finish, ø18 mm
Measuring force:	3 - 8 N
Power supply:	1 battery SR-44
Battery life:	Approx. 2.4 years
Setting standard:	167-327 ø 5 mm
ABS / INC (INC ZERO):	Yes

Auto Power OFF after 20 min. non use: Yes

use:

Low voltage alarm: Yes


Function lock: Yes

HOLD: Yes

2 x PRESET: Yes

Mass: 275 g

Dimensions

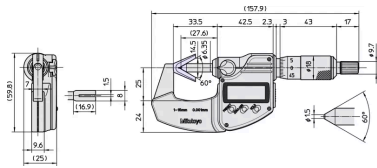

Accessories

Optional accessories:



Micrometer Stand, 45° Angle Type

for Micrometer 0-50mm/0-2"

Art No. 156-105-10

Suggested retail price: 58.00 €*

Promotion!



Micrometer Stand, Adjustable Angle Type

for Micrometer 0-100mm/0-4"

Art No. 156-101-10

Promo price: **55.90 €***

Suggested retail price: 70.00 €*

Promotion!



Connection Unit for IP Caliper, Micrometer

with Data Button for U-WAVE fit, U-WAVE fit Bluetooth

Art No. 02AZF310

Promo price: **74.90 €***

Suggested retail price: 110.00 €*

Promotion!



USB Input Tool Direct (Digimatic to USB)

2m Cable, Digimatic/Digimatic 2, with Data
Button IP Micrometer Type
Art No. 06AFM380B

Promo price: **109.00 €***

Suggested retail price: ~~141.00 €*~~



Digimatic Cable with Data Button IP Type

1m, Micrometer Type
Art No. 05CZA662

Suggested retail price: 105.00 €*



Digimatic Cable with Data Button IP Type

2m, Micrometer Type
Art No. 05CZA663

Suggested retail price: 107.00 €*

Promotion!



U-WAVE fit, IP67 Type

Wireless Transmitter for
Micrometer/Indicator
Art No. 264-622

Promo price: **129.00 €***

Suggested retail price: ~~185.00 €*~~

Promotion!



U-WAVE fit, Buzzer Type

Wireless Transmitter for
Micrometer/Indicator
Art No. 264-623

Promo price: **129.00 €***

Suggested retail price: ~~185.00 €*~~

Promotion!



U-WAVE fit Bluetooth, IP67 Type

Wireless Transmitter for Micrometer/Indicator
Art No. 264-626

Promo price: **139.00 €***
Suggested retail price: ~~185.00 €*~~

Promotion!



U-WAVE fit Bluetooth, Buzzer Type

Wireless Transmitter for Micrometer/Indicator
Art No. 264-627

Promo price: **139.00 €***
Suggested retail price: ~~185.00 €*~~

Promotion!

Mitutoyo

MiCAT

the standard in world metrology software
measurLink

USB-ITPAK Vers. 3.0

USB Dongle + Manual (Software available Online)

Art No. 06AGR543

Promo price: **259.00 €***
Suggested retail price: ~~340.00 €*~~



Standard accessories:



Setting Standard V-Anvil Micrometer

5mm
Art No. 167-327
Suggested retail price: 66.00 €*

Spare parts

Consumable spares:



Battery SR44 1,5 V

Art No. 938882

Suggested retail price: 10.00 €*
