


Digital 3 Flute V-Anvil Micrometer

Item number: 314-262-30

Images

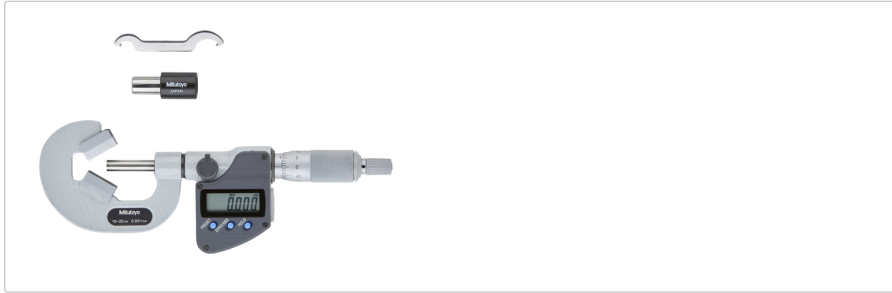

Description

This Digimatic V-Anvil Micrometer helps you to measure cutting tools and taps. It offers the following benefits:

- It measures the outside diameter of cutting tools (such as taps, reamers, end mills) which have three flutes.
- V-anvils with a centreline groove are available for measuring the pitch diameter of taps by the single-wire method.

Features

Digital/Analog:	Digital
Inch-Metric:	Metric
Range:	10 - 25 mm
Digital step:	0,001 mm
Max. Permissible Error J MPE:	±4 µm
Delivered:	Including box, spanner, setting standard, 1 SR44 battery
Anvil:	Without groove
Display:	LCD, character height 7.5 mm
Measuring face:	Prism angle 60°
Measuring spindle:	With spindle lock, ø6,35 mm, spindle pitch 0,75 mm
Scale:	Thimble and sleeve satin chrome finish, ø18 mm
Data output:	Yes
Measuring force:	5 - 10 N
Power supply:	1 battery SR-44
Battery life:	Approx. 2.4 years
Setting standard:	167-328 ø 10 mm
ABS / INC (INC ZERO):	Yes
Auto Power OFF after 20 min. non use:	Yes
Low voltage alarm:	Yes

Promotion!



USB Input Tool Direct (Digimatic to USB)

2m Cable, Digimatic/Digimatic 2, with Data
Button IP Micrometer Type
Art No. 06AFM380B

Promo price: **111.00 €***

Suggested retail price: ~~141.00 €*~~



Digimatic Cable with Data Button IP Type

1 m, Micrometer Type
Art No. 05CZA662

Suggested retail price: 105.00 €*



Digimatic Cable with Data Button IP Type

2 m, Micrometer Type
Art No. 05CZA663

Suggested retail price: 107.00 €*

Promotion!



U-WAVE fit, IP67 Type

Wireless Transmitter for
Micrometer/Indicator
Art No. 264-622

Promo price: **129.00 €***

Suggested retail price: ~~185.00 €*~~

Promotion!



U-WAVE fit, Buzzer Type

Wireless Transmitter for
Micrometer/Indicator
Art No. 264-623

Promo price: **129.00 €***

Suggested retail price: ~~185.00 €*~~

Promotion!



U-WAVE fit Bluetooth, IP67 Type

Wireless Transmitter for Micrometer/Indicator
Art No. 264-626

Promo price: **129.00 €***
Suggested retail price: ~~185.00 €*~~

Promotion!



U-WAVE fit Bluetooth, Buzzer Type

Wireless Transmitter for Micrometer/Indicator
Art No. 264-627

Promo price: **129.00 €***
Suggested retail price: ~~185.00 €*~~

Promotion!

Mitutoyo

MICAT

the standard in world metrology software
measurLink

USB-ITPAK Vers. 3.0

USB Dongle + Manual (Software available Online)

Art No. 06AGR543

Promo price: **268.00 €***
Suggested retail price: ~~340.00 €*~~



Standard accessories:



Setting Standard V-Anvil Micrometer

10mm
Art No. 167-328
Suggested retail price: 70.00 €*

Spare parts

Consumable spares:



Battery SR44 1,5 V

Art No. 938882

Suggested retail price: 7.00 €*
