

## Digital 3 Flute V-Anvil Micrometer

Item number: 314-362-30

### Images



### Description

This Digimatic V-Anvil Micrometer helps you to measure cutting tools and taps. It offers the following benefits:

- It measures the outside diameter of cutting tools (such as taps, reamers, end mills) which have three flutes.
- V-anvils with a centreline groove are available for measuring the pitch diameter of taps by the single-wire method.

### Features

<b>Digital/Analog:</b>	Digital
<b>Inch-Metric:</b>	Inch/Metric
<b>Range:</b>	0,4 - 1 "
<b>Digital step:</b>	0.00005"/0.001 mm
<b>Max. Permissible Error J MPE:</b>	±0.0002"
<b>Delivered:</b>	Including box, spanner, setting standard, 1 SR44 battery
<b>Anvil:</b>	Without groove
<b>Display:</b>	LCD, character height 7.5 mm
<b>Measuring face:</b>	Prism angle 60°
<b>Measuring spindle:</b>	With spindle lock, ø6,35 mm, spindle pitch 0,75 mm
<b>Scale:</b>	Thimble and sleeve satin chrome finish, ø18 mm

<b>Data output:</b>	Yes
<b>Measuring force:</b>	5 - 10 N
<b>Power supply:</b>	1 battery SR-44
<b>Battery life:</b>	Approx. 2.4 years
<b>Setting standard:</b>	167-338 $\varnothing$ 0.4"
<b>ABS / INC (INC ZERO):</b>	Yes
<b>Auto Power OFF after 20 min. non use:</b>	Yes
<b>Low voltage alarm:</b>	Yes
<b>Function lock:</b>	Yes
<b>HOLD:</b>	Yes
<b>2 x PRESET:</b>	Yes
<b>Mass:</b>	410 g

## Accessories

### Optional accessories:



### Micrometer Stand, 45° Angle Type

for Micrometer 0-50mm/0-2"  
 Art No. 156-105-10  
 Suggested retail price: 58.00 €\*

Promotion!



### Micrometer Stand, Adjustable Angle Type

for Micrometer 0-100mm/0-4"  
 Art No. 156-101-10  
 Promo price: **56.00 €\***  
 Suggested retail price: ~~70.00 €\*~~

Promotion!



### Connection Unit for IP Caliper, Micrometer

with Data Button for U-WAVE fit, U-WAVE fit Bluetooth  
 Art No. 02AZF310  
 Promo price: **76.00 €\***  
 Suggested retail price: ~~110.00 €\*~~

Promotion!



### USB Input Tool Direct (Digimatic to USB)

2m Cable, Digimatic/Digimatic 2, with Data  
Button IP Micrometer Type  
Art No. 06AFM380B

Promo price: **111.00 €\***  
Suggested retail price: ~~141.00 €\*~~



### Digimatic Cable with Data Button IP Type

1 m, Micrometer Type  
Art No. 05CZA662  
Suggested retail price: 105.00 €\*



### Digimatic Cable with Data Button IP Type

2 m, Micrometer Type  
Art No. 05CZA663  
Suggested retail price: 107.00 €\*

Promotion!



### U-WAVE fit, IP67 Type

Wireless Transmitter for  
Micrometer/Indicator  
Art No. 264-622

Promo price: **129.00 €\***  
Suggested retail price: ~~185.00 €\*~~

Promotion!



### U-WAVE fit, Buzzer Type

Wireless Transmitter for  
Micrometer/Indicator  
Art No. 264-623

Promo price: **129.00 €\***  
Suggested retail price: ~~185.00 €\*~~

Promotion!



### U-WAVE fit Bluetooth, IP67 Type

Wireless Transmitter for Micrometer/Indicator  
Art No. 264-626

Promo price: **129.00 €\***  
Suggested retail price: ~~185.00 €\*~~

Promotion!



### U-WAVE fit Bluetooth, Buzzer Type

Wireless Transmitter for Micrometer/Indicator  
Art No. 264-627

Promo price: **129.00 €\***  
Suggested retail price: ~~185.00 €\*~~

Promotion!


Mitutoyo

**MICAT**  
the standard in world metrology software  
**measurLink**

### USB-ITPAK Vers. 3.0

USB Dongle + Manual (Software available Online)  
Art No. 06AGR543

Promo price: **268.00 €\***  
Suggested retail price: ~~340.00 €\*~~

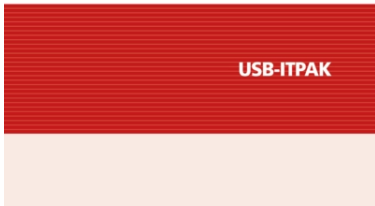

Standard accessories:



### Setting Standard V-Anvil Micrometer

0,4"  
Art No. 167-338  
Suggested retail price: 70.00 €\*

Spare parts

Consumable spares:



## Battery SR44 1,5 V

Art No. 938882

Suggested retail price: 7.00 €\*  

---