
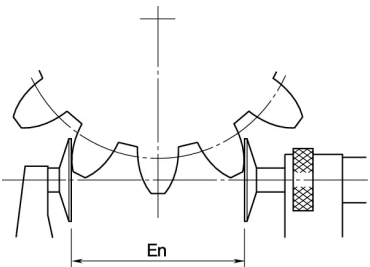


Digital Disc Micrometer IP65

Item number: 323-251-30

Images

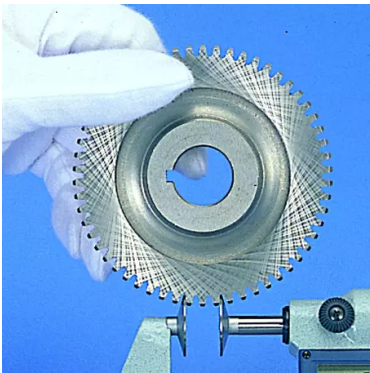

Description

This Digimatic Disc Micrometer enables you to measure hard-to-reach features, offering you the following benefits:


- Measuring the root tangent length of spur and helical gears.
- You can measure recessed features that are difficult to reach with a standard micrometer.

Features

Digital/Analog:	Digital
Inch-Metric:	Metric
Range:	25 - 50 mm
Digital step:	0,001 mm

Max. Permissible Error J MPE:	±4 µm
Delivered:	Including box, spanner, setting standard, 1 SR44 battery
Flatness:	1 µm
Parallelism:	4 µm
Display:	LCD, character height 7.5 mm
Measuring face:	Hardened steel, micro-lap finish
Measuring spindle:	With spindle lock, ø6,35 mm, spindle pitch 0,5 mm
Scale:	Thimble and sleeve satin chrome finish, ø18 mm
Data output:	Yes
Measuring force:	3 - 8 N
Power supply:	1 battery SR-44
Battery life:	Approx. 2.4 years
Measurable module:	0.5 - 6 mm
ORIGIN:	Yes
ABS / INC (INC ZERO):	Yes
Auto Power OFF after 20 min. non use:	Yes
Low voltage alarm:	Yes
Function lock:	Yes
HOLD:	Yes
Mass:	355 g

Dimensions

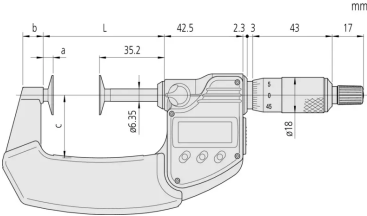

L: 65.6 mm

a: 5.4 mm

b: 11 mm

c: 31 mm

d: 20 mm

Accessories

Optional accessories:



Micrometer Stand, 45° Angle Type

for Micrometer 0-50mm/0-2"

Art No. 156-105-10

Suggested retail price: 58.00 €*
~~58.00 €~~

Promotion!



Micrometer Stand, Adjustable Angle Type

for Micrometer 0-100mm/0-4"

Art No. 156-101-10

Promo price: 56.00 €*
~~70.00 €~~

Suggested retail price: 70.00 €*
~~70.00 €~~

Promotion!



Connection Unit for IP Caliper, Micrometer

with Data Button for U-WAVE fit, U-WAVE fit Bluetooth

Art No. 02AZF310

Promo price: 76.00 €*
~~110.00 €~~

Suggested retail price: 110.00 €*
~~110.00 €~~

Promotion!



USB Input Tool Direct (Digimatic to USB)

2m Cable, Digimatic/Digimatic 2, with Data Button IP Micrometer Type

Art No. 06AFM380B

Promo price: 111.00 €*
~~141.00 €~~

Suggested retail price: 141.00 €*
~~141.00 €~~



Digimatic Cable with Data Button IP Type

1 m, Micrometer Type

Art No. 05CZA662

Suggested retail price: 105.00 €*
~~105.00 €~~



Digimatic Cable with Data Button IP Type

2 m, Micrometer Type

Art No. 05CZA663

Suggested retail price: 107.00 €*
Suggested retail price: 107.00 €*
Suggested retail price: 107.00 €*

Promotion!



U-WAVE fit, IP67 Type

Wireless Transmitter for
Micrometer/Indicator

Art No. 264-622

Promo price: 129.00 €*
Suggested retail price: 185.00 €*

Suggested retail price: 185.00 €*

Promotion!



U-WAVE fit, Buzzer Type

Wireless Transmitter for
Micrometer/Indicator

Art No. 264-623

Promo price: 129.00 €*
Suggested retail price: 185.00 €*

Suggested retail price: 185.00 €*

Promotion!



U-WAVE fit Bluetooth, IP67 Type

Wireless Transmitter for
Micrometer/Indicator

Art No. 264-626

Promo price: 129.00 €*
Suggested retail price: 185.00 €*

Suggested retail price: 185.00 €*

Promotion!



U-WAVE fit Bluetooth, Buzzer Type

Wireless Transmitter for
Micrometer/Indicator

Art No. 264-627

Promo price: 129.00 €*
Suggested retail price: 185.00 €*

Suggested retail price: 185.00 €*

Promotion!

Mitutoyo

MiCAT

the standard in world
metrology software
MeasurLink®

USB-ITPAK Vers. 3.0

USB Dongle + Manual (Software available
Online)

Art No. 06AGR543

Promo price: **268.00 €***

Suggested retail price: ~~340.00 €*~~

USB-ITPAK

Standard accessories:



Micrometer Setting Standard

Length: 25mm

Art No. 167-101

Suggested retail price: **33.00 €***

Spare parts

Consumable spares:



Battery SR44 1,5 V

Art No. 938882

Suggested retail price: **7.00 €***