

Digital Depth Micrometer

Item number: 329-350-30

Images



Description

This interchangeable rod type micrometer can be used for wide range measurements. It offers you the following benefits:


- $\varnothing 4$ mm interchangeable rods, with lapped measuring surfaces, enable you to make wide-range measurement.
- The ratchet stop provides constant measuring force.
- Measuring rod lock.

Features

Inch-Metric:	Inch/Metric
Digital/Analog:	Digital
Power supply:	1 battery SR-44
Range:	0 - 6 "
Digital step:	209-918
Measuring span:	25 mm
Spindle pitch:	0,5 mm
Zero point errors of rods:	$\pm 4 \mu\text{m}$ (0-150 mm) $\pm 6 \mu\text{m}$ (0-300 mm)
Micrometer Head Feed (0-25 mm) (excluding quantizing error):	$\pm 3 \mu\text{m}$
Flatness base:	$2 \mu\text{m}$
Flatness rod:	$0,3 \mu\text{m}$
Parallelism base/rod:	$(4+L/50) \mu\text{m}$ L = max. measuring length (mm)
Measuring face:	Hardened, precision ground, micro-lap finish
Base:	Hardened tool steel

Scale:	Thimble and sleeve satin chrome finish, \varnothing 18 mm
DATA (output with cable) / HOLD (display value):	Yes
Lock function:	Yes
Auto Power OFF after 20 min. non use:	Yes
2 x PRESET:	Yes
Low voltage alarm:	Yes
Base (W x T):	4 x 0.63"
Number of rods:	6
Data output:	Yes
Measuring force:	5-10 N
ABS / INC (INC ZERO):	Yes
Battery life:	Approx. 2,4 years
Mass:	540 g
Delivered:	Including box, spanner no. 301336, 04GAA274, hex-spanner no. 202863, 1 SR44 battery

Dimensions

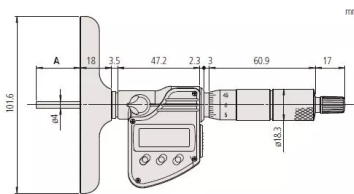



A: 6" / 150 mm

Accessories

Optional accessories:

Promotion!

the standard in world metrology software
MeasurLink

USB-ITPAK Vers. 3.0

USB Dongle + Manual (Software available Online)
Art No. 06AGR543

Promo price: 268.00 €*
~~Suggested retail price: 340.00 €*~~





Digimatic Cable with Data Button IP Type

1 m, Micrometer Type
Art No. 05CZA662
Suggested retail price: 105.00 €*



Digimatic Cable with Data Button IP Type

2 m, Micrometer Type
Art No. 05CZA663
Suggested retail price: 107.00 €*
~~107.00 €*
107.00 €*~~

Promotion!



USB Input Tool Direct (Digimatic to USB)

2m Cable, Digimatic/Digimatic 2, with Data Button IP Micrometer Type
Art No. 06AFM380B
Promo price: **111.00 €*
Suggested retail price: 141.00 €***

Promotion!



U-WAVE fit, IP67 Type

Wireless Transmitter for Micrometer/Indicator
Art No. 264-622
Promo price: **129.00 €*
Suggested retail price: 185.00 €***

Promotion!



U-WAVE fit, Buzzer Type

Wireless Transmitter for Micrometer/Indicator
Art No. 264-623
Promo price: **129.00 €*
Suggested retail price: 185.00 €***

Promotion!



U-WAVE fit Bluetooth, IP67 Type

Wireless Transmitter for Micrometer/Indicator
Art No. 264-626
Promo price: **129.00 €*
Suggested retail price: 185.00 €***

Promotion!



U-WAVE fit Bluetooth, Buzzer Type

Wireless Transmitter for
Micrometer/Indicator
Art No. 264-627

Promo price: **129.00 €***
~~Suggested retail price: 185.00 €*~~

Promotion!



Connection Unit for IP Caliper, Micrometer

with Data Button for U-WAVE fit, U-WAVE fit
Bluetooth
Art No. 02AZF310

Promo price: **76.00 €***
~~Suggested retail price: 110.00 €*~~

Spare parts

Consumable spares:



Battery SR44 1,5 V

Art No. 938882
Suggested retail price: 7.00 €*