


Digital Depth Micrometer

Item number: 329-351-30

Images

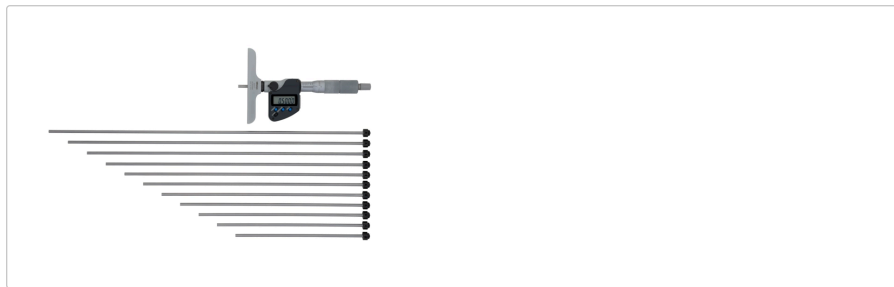

Description

This interchangeable rod type micrometer can be used for wide range measurements. It offers you the following benefits:


- $\varnothing 4$ mm interchangeable rods, with lapped measuring surfaces, enable you to make wide-range measurement.
- The ratchet stop provides constant measuring force.
- Measuring rod lock.

Features

Inch-Metric:	Inch/Metric
Digital/Analog:	Digital
Power supply:	1 battery SR-44
Range:	0 - 12 "
Digital step:	0.0001"/0.001 mm
Measuring span:	25 mm
Spindle pitch:	0,5 mm
Zero point errors of rods:	$\pm 4 \mu\text{m}$ (0-150 mm) $\pm 6 \mu\text{m}$ (0-300 mm)
Micrometer Head Feed (0-25 mm) (excluding quantizing error):	$\pm 3 \mu\text{m}$
Flatness base:	2 μm
Flatness rod:	0,3 μm
Parallelism base/rod:	$(4+L/50) \mu\text{m}$ L = max. measuring length (mm)
Measuring face:	Hardened, precision ground, micro-lap finish
Base:	Hardened tool steel
Scale:	Thimble and sleeve satin chrome finish, $\varnothing 18$ mm
DATA (output with cable) / HOLD (display value):	Yes
Lock function:	Yes
Auto Power OFF after 20 min. non use:	Yes
2 x PRESET:	Yes
Low voltage alarm:	Yes

Base (W x T):	4 x 0.63"
Number of rods:	12
Data output:	Yes
Measuring force:	5-10 N
ABS / INC (INC ZERO):	Yes
Battery life:	Approx. 2,4 years
Mass:	790 g
Delivered:	Including box, spanner no. 301336, 04GAA274, hex-spanner no. 202863, 1 SR44 battery

Dimensions

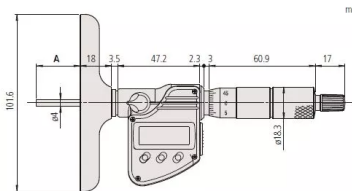



A: 12" / 300 mm

Accessories

Optional accessories:

Promotion!

the standard in world metrology software
MeasurLink

USB-ITPAK Vers. 3.0

USB Dongle + Manual (Software available Online)

Art No. 06AGR543

Promo price: 268.00 €*

Suggested retail price: ~~340.00 €*~~

USB-ITPAK



Digimatic Cable with Data Button IP Type

1 m, Micrometer Type
Art No. 05CZA662
Suggested retail price: 105.00 €*



Digimatic Cable with Data Button IP Type

2 m, Micrometer Type
Art No. 05CZA663
Suggested retail price: 107.00 €*

Promotion!



USB Input Tool Direct (Digimatic to USB)

2m Cable, Digimatic/Digimatic 2, with Data
Button IP Micrometer Type
Art No. 06AFM380B

Promo price: **111.00 €***

Suggested retail price: ~~141.00 €*~~

Promotion!



U-WAVE fit, IP67 Type

Wireless Transmitter for
Micrometer/Indicator
Art No. 264-622

Promo price: **129.00 €***

Suggested retail price: ~~185.00 €*~~

Promotion!



U-WAVE fit, Buzzer Type

Wireless Transmitter for
Micrometer/Indicator
Art No. 264-623

Promo price: **129.00 €***

Suggested retail price: ~~185.00 €*~~

Promotion!



U-WAVE fit Bluetooth, IP67 Type

Wireless Transmitter for
Micrometer/Indicator
Art No. 264-626

Promo price: **129.00 €***

Suggested retail price: ~~185.00 €*~~

Promotion!



U-WAVE fit Bluetooth, Buzzer Type

Wireless Transmitter for
Micrometer/Indicator
Art No. 264-627

Promo price: **129.00 €***

Suggested retail price: ~~185.00 €*~~

Promotion!



Connection Unit for IP Caliper, Micrometer

with Data Button for U-WAVE fit, U-WAVE fit
Bluetooth

Art No. 02AZF310

Promo price: **76.00 €***

~~Suggested retail price: 110.00 €*~~

Spare parts

Consumable spares:



Battery SR44 1,5 V

Art No. 938882

Suggested retail price: 7.00 €*