


## Digital Tubular Inside Micrometer (Rod)

Item number: 337-301

### Images

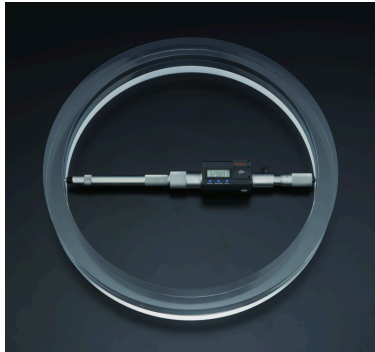

Dust- and  
Water-  
Protected

www.tuv.com  
ID 0000021605



### Description

This is an extension rod type inside micrometer that offers you the following benefits:

- Interchangeable extensions with cylindrical gage rods are spring-mounted in protective sleeves so you can extend the measuring range.
- Carbide measuring faces.
- Digimatic type, with data output.
- It has excellent resistance against water and dust (IP65 protection level) enabling you to use it in machining situations that include splashing coolant fluid.

### Features

<b>Inch-Metric:</b>	Metric
<b>Digital/Analog:</b>	Digital
<b>Range:</b>	200 - 1,000 mm
<b>Measuring span:</b>	25 mm
<b>Digital step:</b>	0,001 mm
<b>Spindle feed error:</b>	3 $\mu$ m
<b>Limit of error:</b>	$\pm(3+\text{number of rods}+\text{max. measurement length}/50)$ $\mu$ m





## Battery SR44 1,5 V

Art No. 938882

Suggested retail price: 7.00 €\*  

---